


# UQV2P2DBH

## Base Product

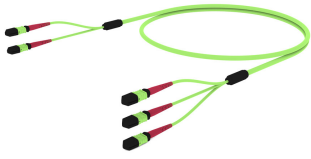

Ultra Low Loss (ULL) OM5 , 2X3, MPO24 (Non-Pinned) to MPO24 (Non-Pinned-QSFP-DD), 48-Fiber, Conversion Array, Plenum

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber conversion array cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	2
<b>Color, boot A</b>	Red
<b>Color, connector A</b>	Lime green
<b>Connector B, quantity</b>	3
<b>Color, boot B</b>	Red
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-24/UPC Female
<b>Interface, Connector B</b>	MPO-24/UPC Female
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	24
<b>Total Fibers, quantity</b>	48

## Dimensions


<b>Breakout Length</b>	12 in   24 in   36 in   48 in   60 in   72 in
------------------------	---

# UQV2P2DBH

**Cable Assembly Length Range (m)** 3 – 305

**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

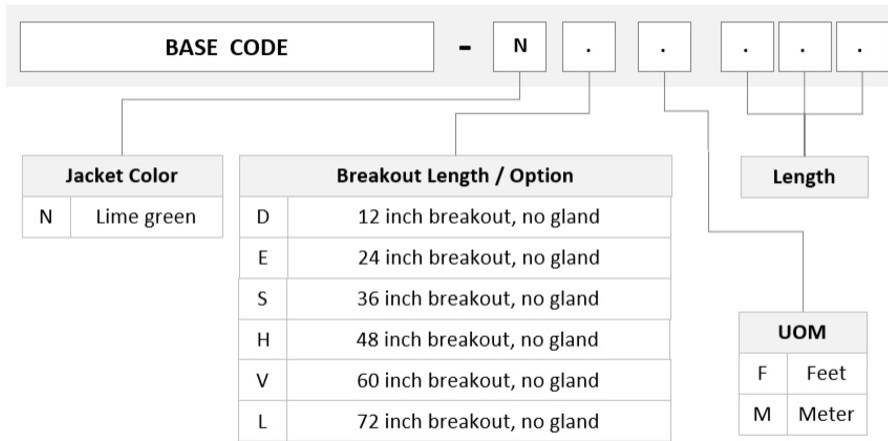

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# UQV2P2DBH

---



## Included Products

- |                                |   |  |
|--------------------------------|---|--|
| 760235977<br>P-048-MP-5G-F24LM | - | Fiber indoor cable, LazrSPEED® Plenum for MPO Trunks, 48 fiber with 24 fiber subunits, Multimode OM5, Feet jacket marking, Lime green jacket color |
| 860634624                      | - | LazrSPEED® Elite MPO Female 24 Fiber Connector, lime green   |
| 860662279                      | - | MPO24,FEMALE,OM5,LIME,3.0MM  |