


UQX2DQP7R

Base Product

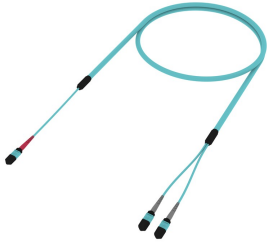

Ultra Low Loss (ULL) OM4, 1X2, MPO24 (Non-Pinned - QSFP-DD) to MPO8 (Non-Pinned), 16-Fiber, Conversion Array, LSZH

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber conversion array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	1
Color, boot A	Red
Color, connector A	Aqua
Connector B, quantity	2
Color, boot B	Gray
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Female
Interface, Connector B	MPO-08/UPC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	16
Total Fibers, quantity	16

Dimensions

UQX2DQP7R

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

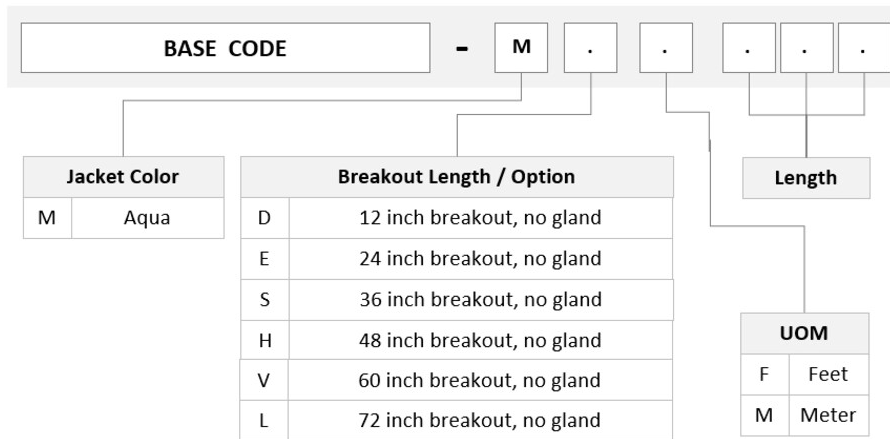

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0° 4.40 lb @ 90°
--	-------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

UQX2DQP7R



Included Products

- | | | |
|-------------------|---|--|
| 760250997 | - | Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 16 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color |
| P-016-MP-5K-F30AQ | - | |
| 860633307 | - | MPO8, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm |
| 860662277 | - | MPO24,FEMALE,OM3/4,AQUA,3.0MM |