


UQX2X2EBH

Base Product

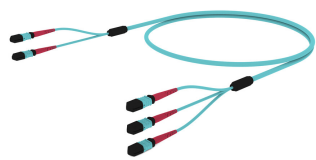

Ultra Low Loss (ULL) OM4, 2X3, MPO24 (Pinned) to MPO24 (Non-Pinned-QSFP), 48-Fiber, Conversion Array, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber conversion array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	2
Color, boot A	Red
Color, connector A	Aqua
Connector B, quantity	3
Color, boot B	Red
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	MPO-24/UPC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	24
Total Fibers, quantity	48

Dimensions

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
-----------------	---

UQX2X2EBH



Included Products

760256579	–	Fiber indoor cable, LazrSPEED® Plenum MPO Trunk Cable, 48 fiber with 24-fiber, 3.0mm
P-048-MP-5K-F24AQ/30T		subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color
860662277	–	MPO24,FEMALE,OM3/4,AQUA,3.0MM
860662278	–	MPO24,MALE,OM3/4,AQUA,3.0MM