


# URGQPLUF8

## Base Product

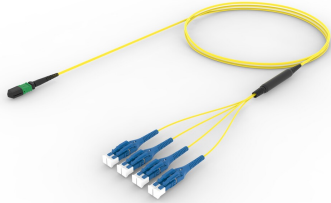

Ultra Low Loss (ULL) Singlemode MPO8 (Non-Pinned) to LC/UPC Uniboot, Fiber Array Cable Assembly, 8-Fiber, Dual Rated (OFNR/LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber array cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	4
<b>Color, boot B</b>	Blue
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-08/APC Female
<b>Interface, Connector B</b>	LC/UPC
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	8

## Dimensions

# URGQPLUF8

<b>Breakout Length</b>	12 in   24 in   48 in   60 in   72 in
<b>Cable Assembly Length Range (m)</b>	1 – 304
<b>Cable Assembly Length Range (ft)</b>	2 – 999

## Ordering Tree

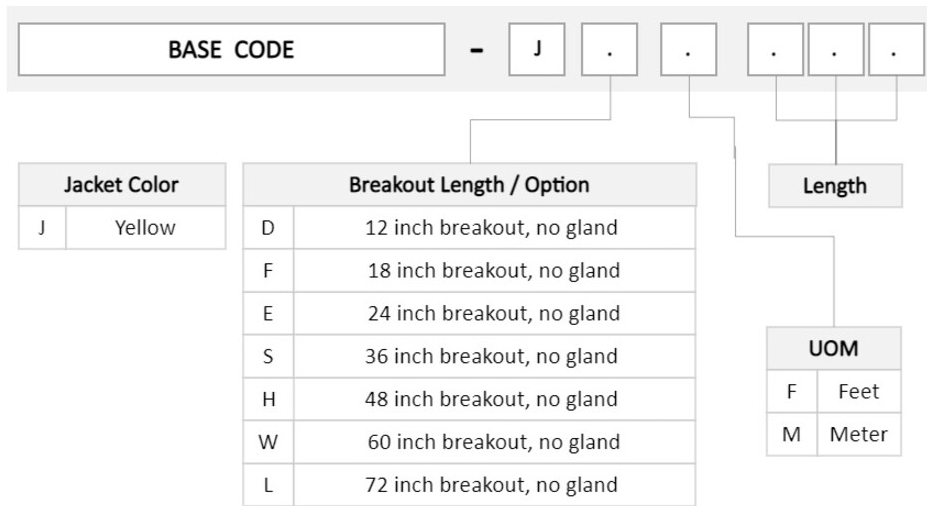

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0°   4.40 lb @ 90°
--	-------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

# URGQPLUF8

---



## Included Products

- 760253739 - Low Smoke Zero Halogen Riser Light Duty Interconnect Cable, 8 fiber  
N-008-MP-8G1-F20YL/E
- 860650412 - TeraSPEED® LC UniBoot 2.0MM UPC/LC UNIBOOT CONNECTOR KIT
- 860659028 - MPO-08, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 2mm