


# URV2P2EBH

Base Product

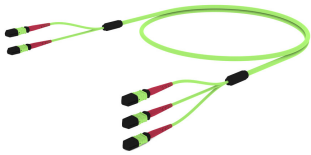

Ultra Low Loss (ULL) OM5 , 2X3, MPO24 (Non-Pinned) to MPO24 (Non-Pinned-QSFP), 48-Fiber, Conversion Array, LSZH

## Product Classification

|                       |  |
|-----------------------|--|
| Regional Availability | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America   |
| Portfolio             | CommScope®   |
| Product Type          | Fiber conversion array cable assembly  |
| Product Brand         | Propel   SYSTIMAX ULL  |
| Ordering Note         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                              |                         |
|------------------------------|-------------------------|
| Connector A, quantity        | 2                       |
| Color, boot A                | Red                     |
| Color, connector A           | Lime green              |
| Connector B, quantity        | 3                       |
| Color, boot B                | Red                     |
| Color, connector B           | Lime green              |
| Construction Type            | Stranded                |
| Furcation Color              | Lime green              |
| Interface, Connector A       | MPO-24/UPC Female       |
| Interface, Connector B       | MPO-24/UPC Female       |
| Jacket Color                 | Lime green              |
| Polarity                     | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 24                      |
| Total Fibers, quantity       | 48                      |


## Dimensions

|                 |   |
|-----------------|---|
| Breakout Length | 12 in   24 in   36 in   48 in   60 in   72 in |
|-----------------|---|

# URV2P2EBH

|                                  |          |
|----------------------------------|----------|
| Cable Assembly Length Range (m)  | 3 – 305  |
| Cable Assembly Length Range (ft) | 10 – 999 |

## Ordering Tree

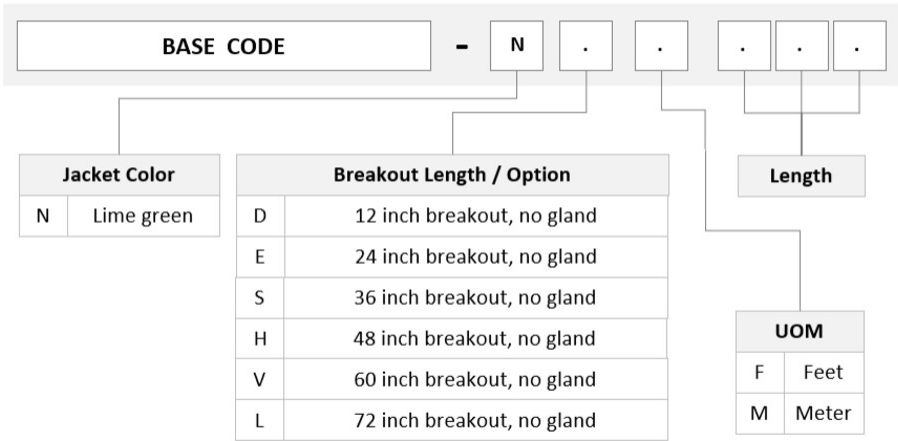

## Mechanical Specifications

|                                   |                                 |
|-----------------------------------|---------------------------------|
| Cable Retention Strength, maximum | 11.24 lb @ 0 °   4.40 lb @ 90 ° |
|-----------------------------------|---------------------------------|

## Optical Specifications

|            |                 |
|------------|-----------------|
| Fiber Mode | Multimode       |
| Fiber Type | OM5, LazrSPEED® |

## Environmental Specifications

|                       |                                      |
|-----------------------|--------------------------------------|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
| Environmental Space   | Dual Rated LSZH/Riser   Indoor       |

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |

# URV2P2EBH

---



## Included Products

|                                       |   |  |
|---------------------------------------|---|--|
| 760255397<br>N-048-MP-5G-F24LM/30T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber with 24-fiber, 3.0 mm subunits, Multimode OM5, Feet jacket marking, Aqua jacket color, B2ca flame rating |
| 860662279                             | - | MPO24,FEMALE,OM5,LIME,3.0MM  |