


# URV2X2EBH

## Base Product

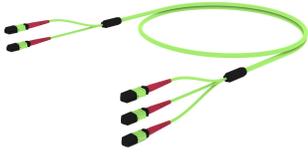

Ultra Low Loss (ULL) OM4, 2X3, MPO24 (Pinned) to MPO24 (Non-Pinned-QSFP), 48-Fiber, Conversion Array, LSZH

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber conversion array cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	2
<b>Color, boot A</b>	Red
<b>Color, connector A</b>	Lime green
<b>Connector B, quantity</b>	3
<b>Color, boot B</b>	Red
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-24/UPC Male
<b>Interface, Connector B</b>	MPO-24/UPC Female
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	24
<b>Total Fibers, quantity</b>	48


## Dimensions

<b>Breakout Length</b>	12 in   24 in   36 in   48 in   60 in   72 in
------------------------	---

# URV2X2EBH

<b>Cable Assembly Length Range (m)</b>	3 – 305
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

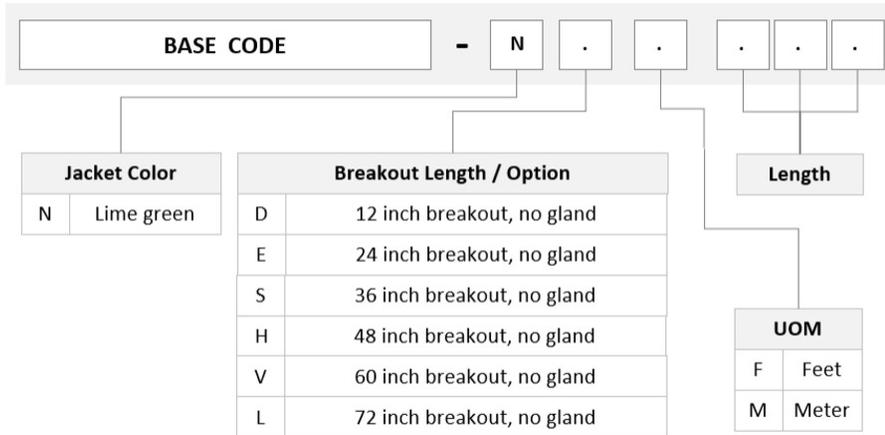

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0 °   4.40 lb @ 90 °
--	---------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM5, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# URV2X2EBH

---



## Included Products

- |                                       |   |  |
|---------------------------------------|---|--|
| 760255397<br>N-048-MP-5G-F24LM/30T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber with 24-fiber, 3.0 mm subunits, Multimode OM5, Feet jacket marking, Aqua jacket color, B2ca flame rating |
| 860662279                             | - | MPO24,FEMALE,OM5,LIME,3.0MM  |
| 860662280                             | - | MPO24,MALE,OM5,LIME,3.0MM  |