


URXQVQVF8

Base Product

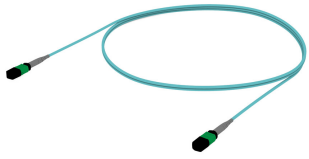

Ultra Low Loss (ULL) OM4 MPO8 APC (Non-Pinned) to MPO8 APC (Non-Pinned), Fiber Trunk Cable Assembly, 8-Fiber, Dual Rated (OFNR /LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber array cable assembly

Product Brand

Propel | SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	1
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	MPO-08/APC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8


Dimensions

Cable Assembly Length Range (m)	1 – 305
--	---------

URXQVQVF8

Cable Assembly Length Range (ft) 3 – 999

Ordering Tree

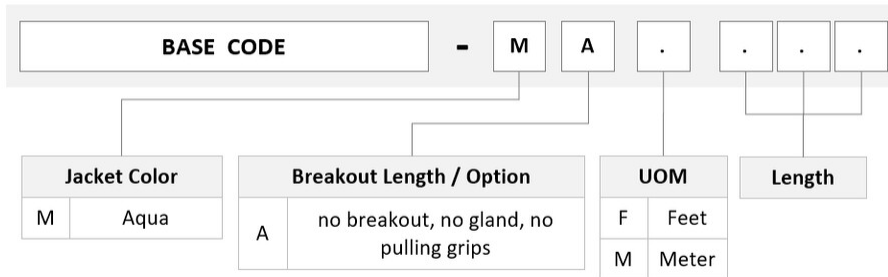

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

Included Products

- 760251447 N-008-MP-5K-F20AQ/E – LazrSPEED® Low Smoke Zero Halogen Riser Light Duty Interconnect Cable, 8 fiber
- 860662232 – MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm