

# CM-30T-B



Chain Mount Base Kit, 8 ft chain

## Product Classification

**Product Type** Chain mount kit

## General Specifications


**Chains, quantity** 2  
**Pipe, quantity** 0  
**Sectors, quantity** 3

## Dimensions

**Height** 152.4 mm | 6 in  
**Width** 203.2 mm | 8 in  
**Length** 203.2 mm | 8 in  
**Chain Length** 2,400.3 mm | 94.5 in  
**Mounting Diameter, maximum** 762 mm | 30 in  
**Mounting Diameter, minimum** 203.2 mm | 8 in  
**Pipe Outer Diameter** 60.96 mm | 2.4 in  
**Mounting Circumference, maximum** 2,392.68 mm | 94.2 in  
**Mounting Circumference, minimum** 635 mm | 25 in

# CM-30T-B

## Outline Drawing

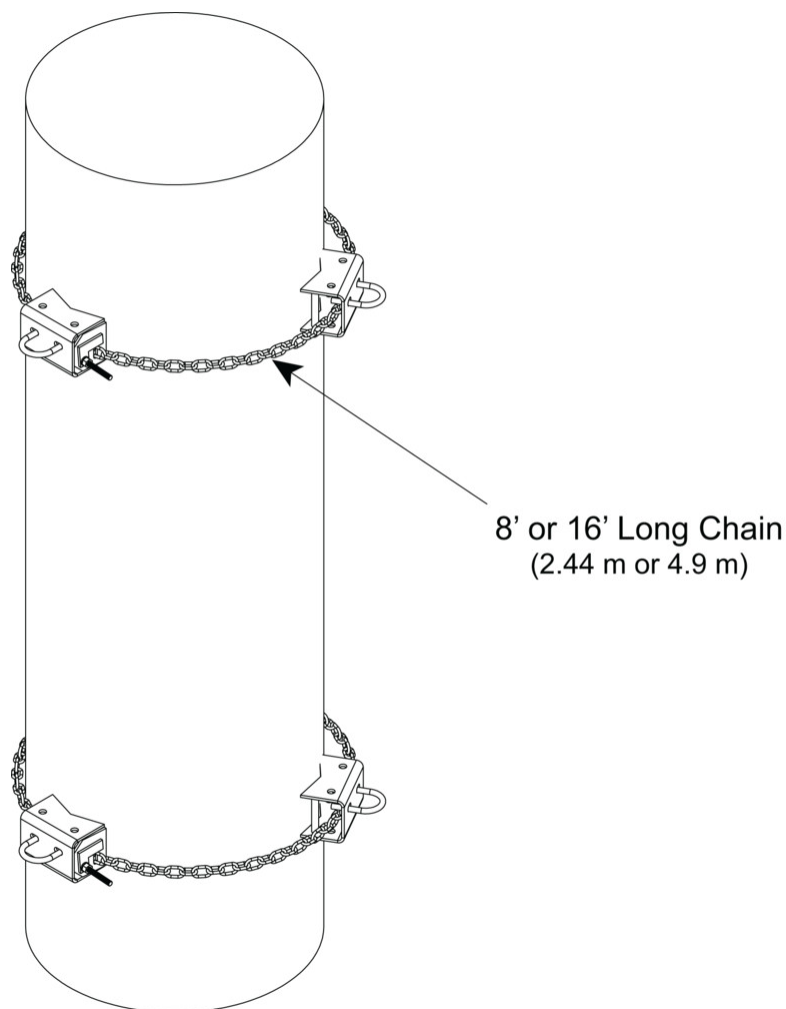

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** 120 mph (BWS) at 100 ft AGL

**Wind Rating Criteria** One 96 in x 10 in panel antenna per sector

**Wind Rating Test Method** TIA/EIA-222

## Packaging and Weights

**Included** Chains

# CM-30T-B

---

Packaging quantity	1
Weight, net	23 kg   50.706 lb

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

## \* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--