

Copper Cable, category 3, 25 pair, U/UTP, LSZH rated, 3300 ft, gray



- Exceptional 100-Ohm series cables for both analog and digital services
- Meets or exceeds industry requirements and environmental regulations
- Small outside diameter and cross-sectional area in bundles and cable
- Innovative design and enhanced electrical and mechanical performance

Product Classification

Regional Availability	Asia
Portfolio	NETCONNECT®
Product Type	Twisted pair cable


General Specifications

ANSI/TIA Category	3
Cable Component Type	Horizontal
Cable Type	U/UTP (unshielded)
Conductor Type, singles	Solid
Conductors, quantity	50
Jacket Color	Gray
Pairs, quantity	25
Transmission Standards	ANSI/TIA-568-D.2

Dimensions

Cable Length	1,005.84 m   3300 ft
Diameter Over Jacket, nominal	8.992 mm   0.354 in
Conductor Gauge, singles	26 AWG

Cross Section Drawing

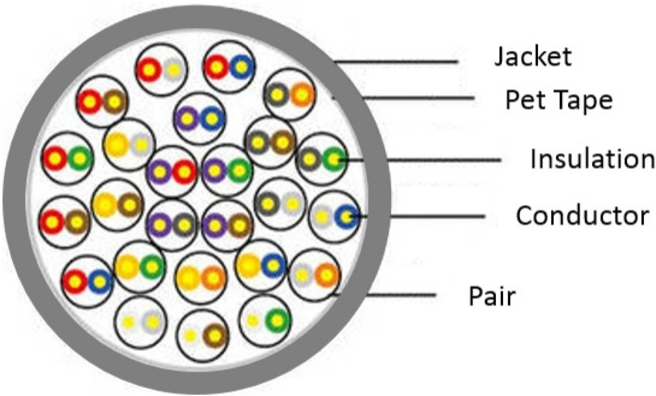

Electrical Specifications

Characteristic Impedance	100 ohm
Characteristic Impedance Tolerance	±15 ohm
dc Resistance, maximum	14 ohms/100 m   4.267 ohms/100 ft
Mutual Capacitance at Frequency	5.6 nF/100 m @ 1 kHz
Operating Voltage, maximum	80 V

Material Specifications

Conductor Material	Bare copper
Insulation Material	Polyolefin
Jacket Material	Low Smoke Zero Halogen (LSZH)

Mechanical Specifications

Minimum Bend Radius, multiple Bends	36 mm   1.417 in
-------------------------------------	------------------

Environmental Specifications

Operating Temperature	-20 °C to +60 °C (-4 °F to +140 °F)
Storage Temperature	-20 °C to +70 °C (-4 °F to +158 °F)
Flame Test Method	NEC Article 800   UL 444

Packaging and Weights

5-1859748-4

---

Packaging Type

Reel