

CM-60T-96



Chain Mount Kit, 16 ft chain, includes pipe

Product Classification

Product Type	Chain mount kit
Ordering Note	ANDREW® non-standard product
Warranty	One year

General Specifications


Chains, quantity	2
Pipe, quantity	3
Sectors, quantity	3

Dimensions

Height	152.4 mm 6 in
Width	203.2 mm 8 in
Length	2,438.4 mm 96 in
Chain Length	4,902.2 mm 193 in
Pipe Length	2,438.4 mm 96 in
Mounting Diameter, maximum	1524 mm 60 in
Mounting Diameter, minimum	203.2 mm 8 in
Pipe Outer Diameter	60.96 mm 2.4 in
Mounting Circumference, maximum	4,775.2 mm 188 in
Mounting Circumference, minimum	635 mm 25 in

CM-60T-96

Outline Drawing

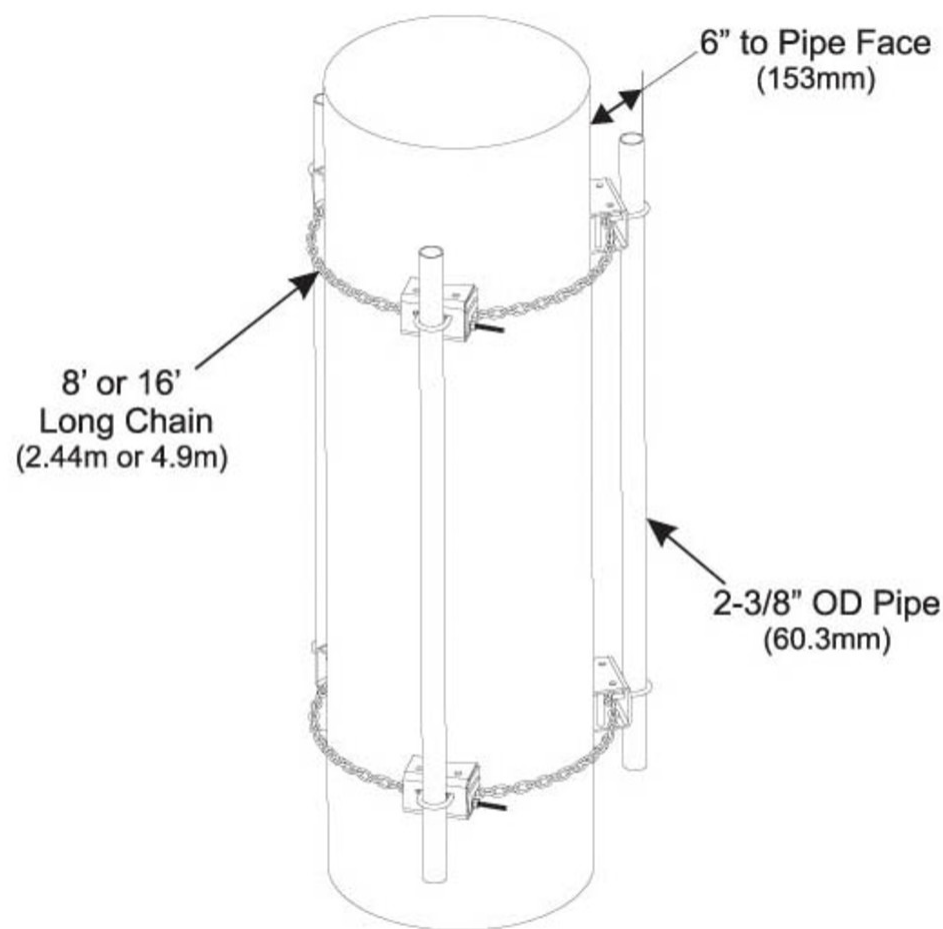

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating 120 mph (BWS) at 100 ft AGL

Wind Rating Criteria One 96 in x 10 in panel antenna per sector

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Chains | Plain end pipes

CM-60T-96

Packaging quantity	1
Weight, net	74.1 kg 163.362 lb

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

Included Products

CM-60T-B	– Chain Mount Base Kit, 16 ft chain
MT-651-96	– Plain End Pipe, 2-3/8 in OD x 96 in .120" A500C 46Ksi

* Footnotes

Warranty	For more information, please consult our Product Warranty guidelines
Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code