

CM-H30-63



Heavy Duty Chain Mount Kit, 8 ft chain, includes pipe

Product Classification

Product Type Chain mount kit

General Specifications


Chains, quantity 4
Pipe, quantity 1
Sectors, quantity 1

Dimensions

Height 152.4 mm | 6 in
Width 203.2 mm | 8 in
Length 1,600.2 mm | 63 in
Chain Length 2,400.3 mm | 94.5 in
Pipe Length 1,600.2 mm | 63 in
Mounting Diameter, maximum 762 mm | 30 in
Mounting Diameter, minimum 203.2 mm | 8 in
Pipe Outer Diameter 114.3 mm | 4.5 in
Mounting Circumference, maximum 2,392.68 mm | 94.2 in
Mounting Circumference, minimum 635 mm | 25 in

CM-H30-63

Outline Drawing

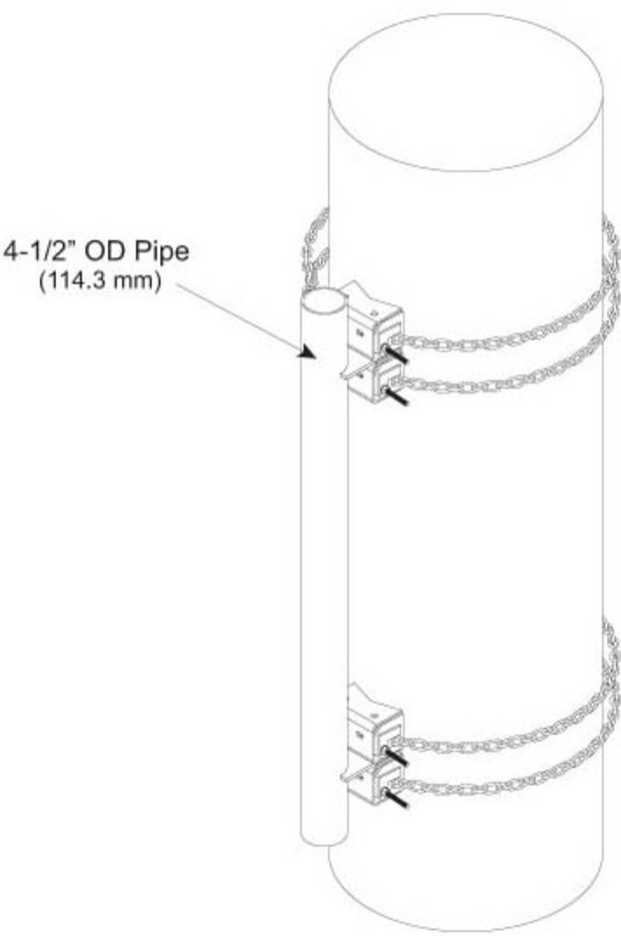

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating 125 mph (BWS) at 100 ft AGL

Wind Rating Criteria One 8 ft standard microwave antenna, with radome and stiff arm

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Chains | Pipe mounts

CM-H30-63

Packaging quantity	1
Weight, net	52.9 kg 116.624 lb

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

Included Products

CM-H30-B	– Heavy Duty Chain Mount Kit, 8 ft chain
MT-395	– Standard Pipe Mount, 4-1/2 in OD x 63 in

* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--