


URXMXLUUD

Base Product

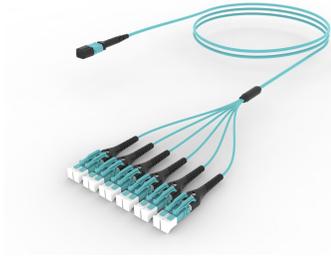

Ultra Low Loss (ULL) OM4 MPO12 (Pinned) to LC Uniboot, Fiber Array Cable Assembly, 12-Fiber, Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Black
Color, connector A	Aqua
Connector B, quantity	6
Color, boot B	Black
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12


Dimensions

URXMXLUUD

Cable Assembly Length Range (m) 1 – 304

Cable Assembly Length Range (ft) 2 – 999

Ordering Tree

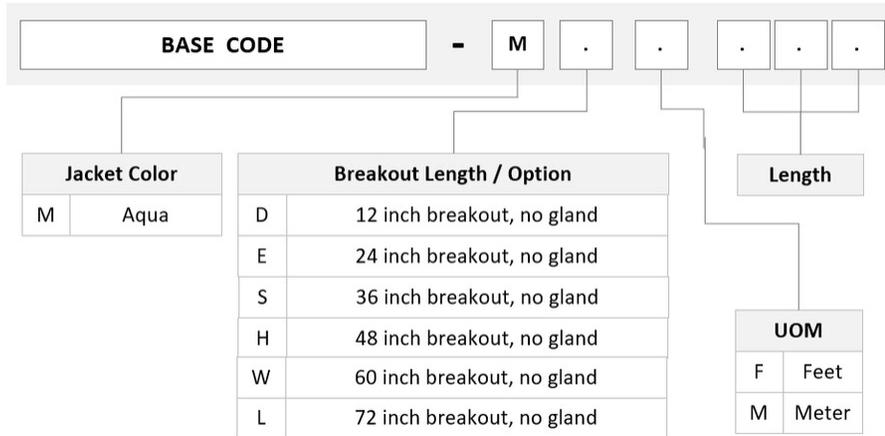

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance Dca

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

URXMXLUUD

UK-ROHS

Compliant



Included Products

- | | | |
|---------------------|---|---|
| 760229195 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty Interconnect, 12 |
| N-012-MP-5K-F20AQ/E | | fiber, Multimode OM4, Feet jacket marking, Aqua jacket color, Eca flame rating |
| 860366228 | - | MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm |
| 860658161 | - | 2.0 mm LC/UPC Uniboot GEN 1.5, Aqua |