


MC-K6MHDX-9-96

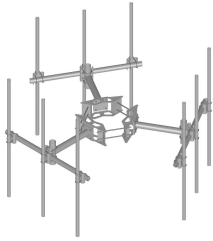

Monopole High Capacity T-Frame kit, 12in to 50in OD, 6.5ft x 3.5in OD face, includes (9) 2-7/8in OD x 96in antenna pipes

Product Classification

Portfolio	CommScope®
Product Type	Monopole T-frame kit
Ordering Note	CommScope® non-standard product
Warranty	One year

General Specifications

Mounting	Monopole, 304.8–1270 mm (12–50 in) OD
Pipe, quantity	9
Sectors, quantity	3

Dimensions

Height	2,438.4 mm 96 in
Face Width	1.981 m 6.5 ft
Width	2,133.6 mm 84 in
Pipe Length	2,438.4 mm 96 in
Face Support Pipe Diameter	88.9 mm 3.5 in
Mounting Diameter, maximum	1270 mm 50 in
Mounting Diameter, minimum	304.8 mm 12 in
Pipe Outer Diameter	73.025 mm 2.875 in
Stand-off Distance	914.4 mm 36 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Mechanical Specifications

Wind Rating Test Method	TIA/EIA-222-G
--------------------------------	---------------

MC-K6MHDX-9-96

Packaging and Weights

Included	Pipe mounts Plain end pipes (9) Ring mount Stand-off arms
Packaging quantity	1
Weight, net	545.672 kg 1203 lb

* Footnotes

Warranty For more information, please consult our Product Warranty guidelines