


CAF-LCLC-LSON

Base Product

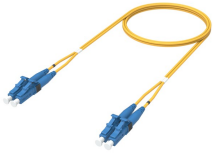

Armored Jumper G657.A2 LC/UPC to LC/UPC Duplex, 3.0mm LSZH, Yellow

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China India North America |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, duplex |
| Product Series | CAF |

General Specifications

| | |
|-------------------------------|----------------|
| Connector A, quantity | 2 |
| Color, boot A | Blue |
| Color, connector A | Blue |
| Connector B, quantity | 2 |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Construction Type | Armored |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | LC/UPC |
| Jacket Color | Yellow |
| Polarity | Pairs, flipped |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|---|-----------------|
| Cable Assembly Length Range (m) | 1 – 300 |
| Cable Assembly Length Range (ft) | 3 – 999 |
| Diameter Over Jacket | 3 mm 0.118 in |

Mechanical Specifications

| | |
|---|--------------------|
| Tensile Load, long term, maximum | 200 N 44.962 lbf |
|---|--------------------|

CAF-LCLC-LSON

| | |
|--|--------------------|
| Tensile Load, short term, maximum | 400 N 89.924 lbf |
| Cable Retention Strength, maximum | 15.43 lb @ 0° |

Optical Specifications

| | |
|--------------------------------|----------------------|
| Fiber Mode | Singlemode |
| Fiber Type | G.657.A2, TeraSPEED® |
| Insertion Loss, maximum | 0.25 dB |
| Return Loss, minimum | 50 dB |

Environmental Specifications

| | |
|--------------------------------|--------------------------------------|
| Operating Temperature | -25 °C to +70 °C (-13 °F to +158 °F) |
| Environmental Space | Low Smoke Zero Halogen (LSZH) |
| Qualification Standards | IEC 61753-1, category OP |

Packaging and Weights

| | |
|---------------------------|---|
| Packaging quantity | 1 |
|---------------------------|---|