


UJGMPUCDM

Base Product

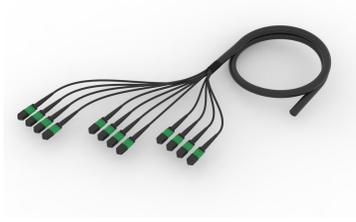

Ultra Low Loss (ULL) Singlemode, MPO12 Unpinned to Unconnectorized, Fiber Trunk Cable Assembly, 144-Fiber, Low Smoke Zero Halogen/Riser, Indoor/Outdoor

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Green
Construction Type	Stranded
Furcation Color	Black
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	Unterminated
Jacket Color	Black
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	144

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

UJGMPUCDM

- 760238831
Z-144-MP-8G-F12BK/D - Indoor/Outdoor Low Smoke Zero Halogen Riser MPO Trunk Cable, 144 fiber multi-unit with 12 fiber subunits
- 860638318 - MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm