


MC-HP14S-12-96

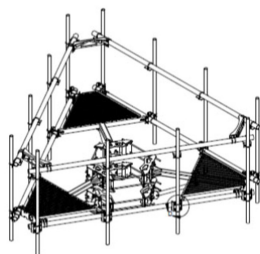

3-Sector Monopole Co-location Platform Kit, 10 in to 30 in OD, 14 ft 6 in face, includes twelve 96 in pipes

OBSOLETE

This product was discontinued on: March 9, 2022

Replaced By:

MC-HP14M-12-96	3-Sector Monopole Co-location Platform Kit, 12 in to 50 in OD, 14 ft 6 in face, includes twelve 96 in pipes
----------------	---

Product Classification

Product Type	Monopole platform kit
--------------	-----------------------

General Specifications

Mounting	Monopole, 254–762 mm (10–30 in) OD
Pipe, quantity	12
Sectors, quantity	3

Dimensions

Height	2,438.4 mm 96 in
Face Width	4.42 m 14.5 ft
Width	4,419.6 mm 174 in
Pipe Length	2,438.4 mm 96 in
Mounting Diameter, maximum	762 mm 30 in
Mounting Diameter, minimum	254 mm 10 in
Pipe Outer Diameter	60.96 mm 2.4 in

Material Specifications

Material Type	Hot dip galvanized steel
---------------	--------------------------

Mechanical Specifications

MC-HP14S-12-96

Wind Rating	120 mph (BWS) at 100 ft AGL 140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC
Wind Rating Test Method	TIA/EIA-222

Packaging and Weights

Included	Plain end pipes (12) Platform Rail Ring mount
Packaging quantity	1
Weight, net	1,030.108 kg 2271 lb

* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--