


# MC-RR1050-3

---

## Three Sector Dual Radio Ring Mount

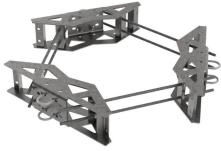

### Product Classification

**Product Type** Universal ring mount

### General Specifications

**Mounting** Monopole, 254–1270 mm (10–50 in) OD

**Pipe, quantity** 0

**Sectors, quantity** 3

### Dimensions

**Height** 203.2 mm | 8 in

**Length** 152.4 mm | 6 in

**Mounting Diameter, maximum** 1270 mm | 50 in

**Mounting Diameter, minimum** 254 mm | 10 in

**Pipe Outer Diameter** 0 mm | 0 in

**Mounting Circumference, maximum** 3,990.34 mm | 157.1 in

**Mounting Circumference, minimum** 797.56 mm | 31.4 in

### Material Specifications

**Material Type** Hot dip galvanized steel

### Packaging and Weights

**Included** Hardware | Mount

**Packaging quantity** 1

**Weight, net** 45.722 kg | 100.8 lb

# MC-RR1050-3

---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

