



This product was discontinued on: July 29, 2022

MCG22HDX-14M12-126	G22HDX High Capacity 3-Sector Monopole Frame with 2 7/8in OD x 14.5ft face. Includes twelve 2 7/8in OD x 126in antenna pipes
--------------------	--

Product Type	High capacity monopole sector frame
---------------------	-------------------------------------

General Specifications

Pipe, quantity	12
-----------------------	----

Dimensions

Face Width 4.42 m | 14.5 ft

Pipe Length 3,200.4 mm | 126 in


Mounting Diameter, maximum	1270 mm 50 in
-----------------------------------	-----------------

Pipe Outer Diameter	60.325 mm 2.375 in
----------------------------	----------------------

Stand-off Distance 1,117.6 mm | 44 in.

Page 1 of 3

MCG22-14M-12-126

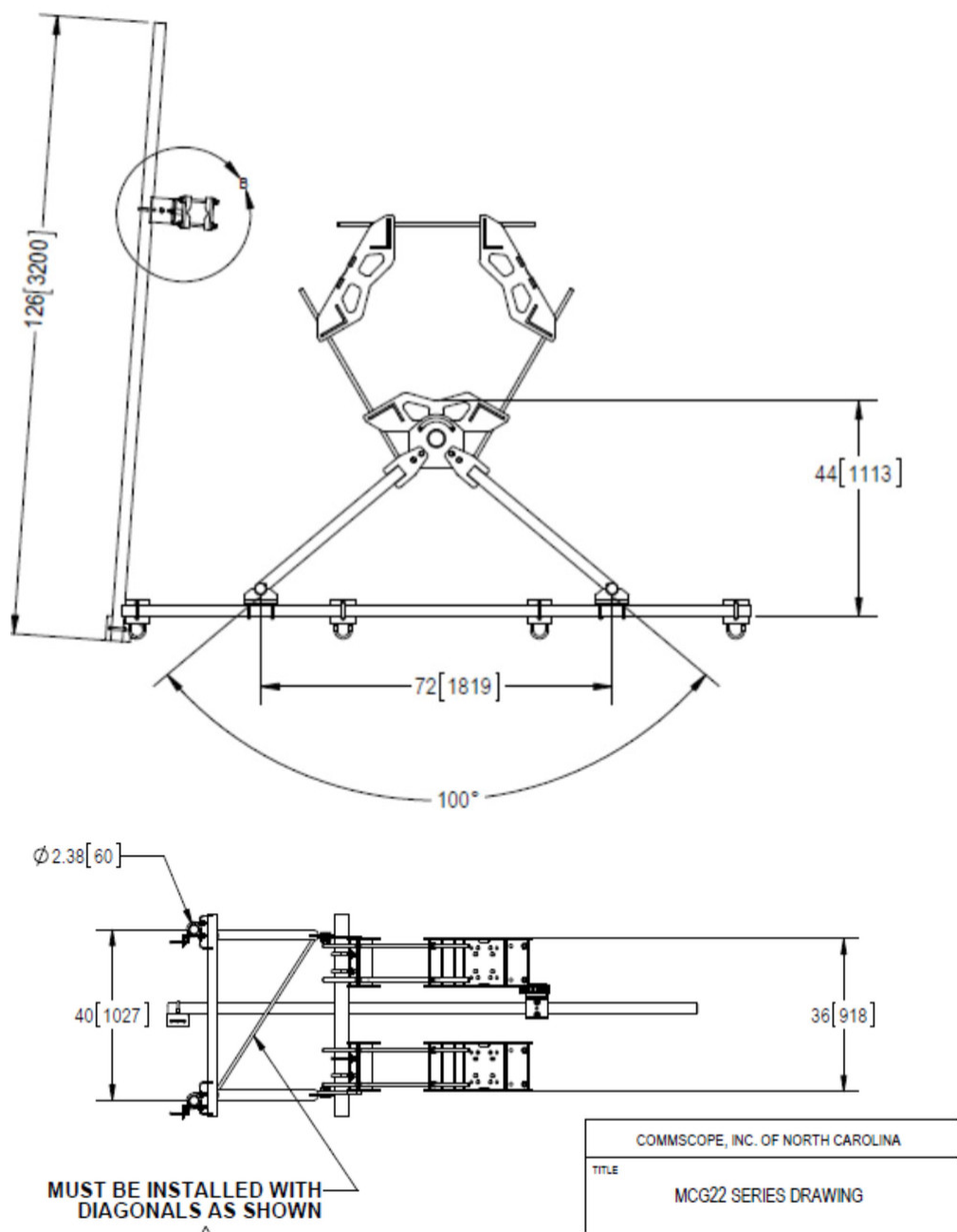

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Load Capacity With additional stiff arm at 300 ft AGL: 600 lb per pipe w/out ice / 1275 lb per pipe including ice

MCG22-14M-12-126

Wind Rating	For Specifications, please contact your local ANDREW representative
Wind Rating Test Method	TIA/EIA-222
Wind Rating with Additional Stiff Arm	300 ft AGL: 120 mph (BWS) without ice /60 mph with ice

Packaging and Weights

Included	Pipe mounts Plain end pipes (12) Ring mounts (2) Sector frames (3) Stiff arm
Packaging quantity	1
Weight, net	968.873 kg 2136 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
Wind Rating with Additional Stiff Arm	BWS—Base Wind Speed; FBC—Florida Building Code