


# 760254739 | C-008-CN-8W-M08BK/28D/GY/D

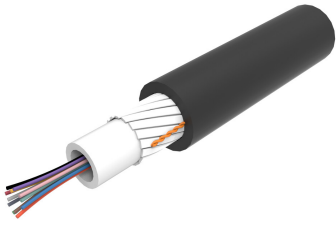

Indoor/Outdoor Low Smoke Zero Halogen, TeraSPEED® Central Loose Tube Fiber Optic Cable, 8-fiber, Singlemode OS2, Gel-free, black. Provides Rodent Resistance.

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber indoor/outdoor cable
<b>Product Series</b>	C-CN


## General Specifications

<b>Cable Type</b>	Loose tube
<b>Subunit Type</b>	Gel-free
<b>Jacket Color</b>	Black
<b>Jacket Marking</b>	Meters
<b>Jacket Marking Method</b>	Inkjet
<b>Jacket Marking Text</b>	COMMSCOPE GB OPTICAL CABLE 760254739 INT/EXT RODENT RESISTANT DLT 8X9/125 OS2 EN50575 CLASS D (Serial NUMBER) (METRE MARK)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fiber Count</b>	4

## Dimensions

<b>Cable Length</b>	4000 m   13,123.36 ft
<b>Diameter Over Jacket</b>	6.4 mm   0.252 in

## Representative Image

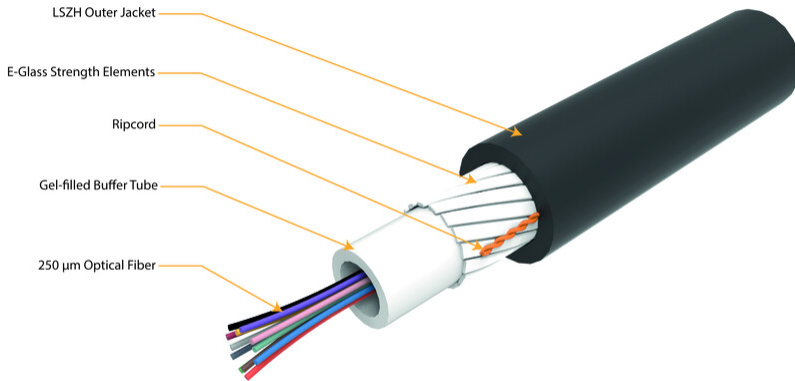

## Mechanical Specifications

<b>Minimum Bend Radius, loaded</b>	139.7 mm   5.5 in
<b>Minimum Bend Radius, unloaded</b>	129.5 mm   5.098 in
<b>Tensile Load, long term, maximum</b>	650 N   146.126 lbf
<b>Tensile Load, short term, maximum</b>	1250 N   281.011 lbf

## Optical Specifications

**Fiber Type** G.652.D and G.657.A1, TeraSPEED® | OS2

## Optical Specifications, Wavelength Specific

**Attenuation, maximum** 0.35 dB/km @ 1,300 nm | 0.35 dB/km @ 1,550 nm | 0.45 dB/km @ 1,310 nm

**Standards Compliance** IEC 60794-1 | TIA-492CAAB (OS2)

## Environmental Specifications

<b>Operating Temperature</b>	-20 °C to +70 °C (-4 °F to +158 °F)
<b>Storage Temperature</b>	-10 °C to +70 °C (+14 °F to +158 °F)
<b>EN50575 CPR Cable EuroClass Fire Performance</b>	Dca
<b>EN50575 CPR Cable EuroClass Smoke Rating</b>	s2
<b>EN50575 CPR Cable EuroClass Droplets Rating</b>	d2
<b>EN50575 CPR Cable EuroClass Acidity Rating</b>	a1

## Environmental Space

Low Smoke Zero Halogen (LSZH)

## Packaging and Weights

### Cable weight

47 kg/km | 31.583 lb/kft

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant



## Included Products

CS-8W-LT - TeraSPEED® G652D/G657A1 Singlemode Fiber

## \* Footnotes

**Operating Temperature** Specification applicable to non-terminated bulk fiber cable