


2160937-1 | OCP-SF-02MASEN-XX-(12COL)

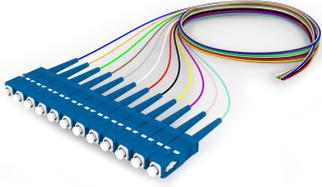

Fiber Optic Pigtail, Simplex, Singlemode, SC/UPC to Stub, 0.9 mm diameter, multicolor, 2 m

- Semi-tight cable stripping performance: 2 meter in steps of min. 30cm (in one operation). Applied force to remove each section is 10 N.

Product Classification

Regional Availability	EMEA
Product Type	Fiber pigtail, jacketed
Product Series	OCP

General Specifications

Connector A, quantity	12
Color, boot A	Blue
Color, connector A	Blue
Interface, Connector A	SC/UPC
Total Fibers, quantity	12

Dimensions

Cord Length	2 m 6.562 ft
--------------------	----------------

Ordering Tree

2160937-1 | OCP-SF-02MASEN-XX-(12COL)



Connector/adaptor type		
Standard C grade	Superior B grade	Type
S1	SF	SC/UPC
S2	SG	SC/APC 8°
S3	SH	SC/APC 9°
L1	LF	LC/UPC
L2	LG	LC/APC
-	EC	LSH/APC 8°

Cable type			Fiber type
ASEN	900 µm	Semi-tight jacket	A1
HSEN	900 µm	Semi-tight jacket	A2

Cable length	
02	2 meters

- Standard Configuration by default 900µm buffer
 buffer color : yellow
 250 µm color : natural or milky white

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A1, TeraSPEED®

Environmental Specifications

Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

