


ALGMPLUCD

Base Product

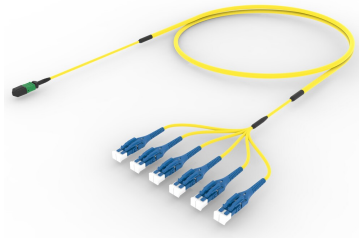

Ultra Low Loss ULL TeraSPEED® MPO(Non-Pinned) to LC/UPC Uniboot Ruggedized fanout Cable, 12-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Black

Color, connector A

Green

Color, boot B

Blue

Color, connector B

Blue

Construction Type

Stranded

Furcation Color

Yellow

Interface, Connector A

MPO-12/APC Female

Interface, Connector B

LC/UPC

Interface Feature, connector B

Uniboot

Jacket Color

Yellow

Polarity

Method A

Fibers per Subunit, quantity

12

Total Fibers, quantity

12

Dimensions

Cable Assembly Length Range (m)


3 – 999

ALGMPLUCD

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

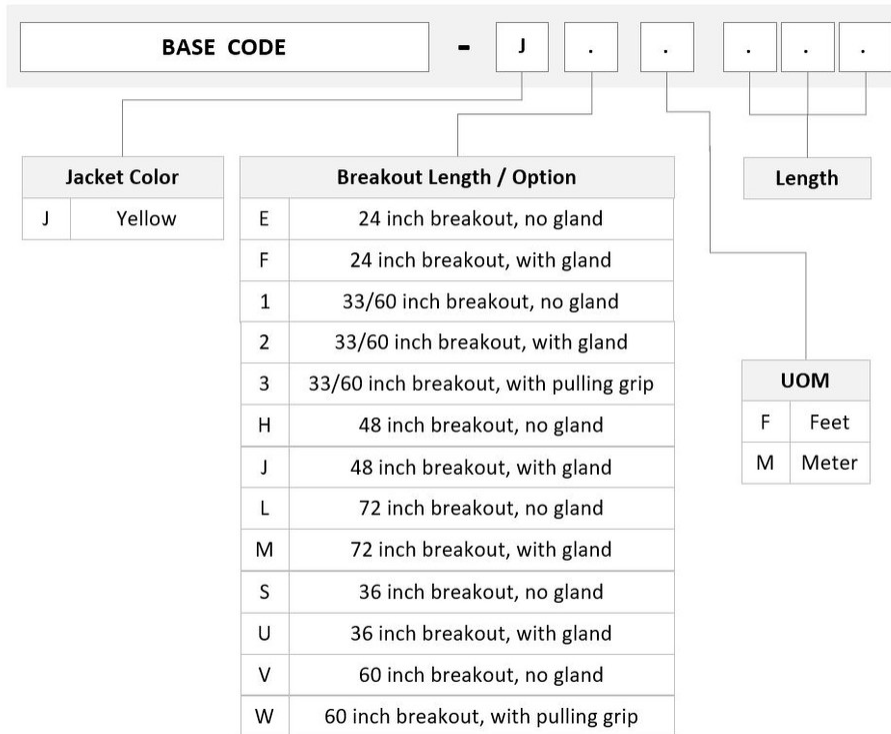

Optical Specifications

Fiber Mode

Singlemode

Fiber Type

G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Indoor | Plenum

Included Products

760242049

P-012-MP-8G-F12YL/20T

860638318

- Fiber indoor cable, Plenum for MPO Trunks, 12 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color
- MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm

ALGMPLUCD

860658160

– LC/UPC Uniboot Connector, Singlemode, Blue