


ARGMXCSGD

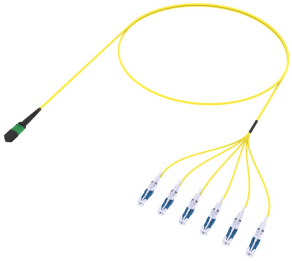

Singlemode MPO12 (pinned) to CS/UPC 12-Fiber Low Smoke Zero Halogen Array Cord

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East /Africa | North America

Portfolio

CommScope®

Product Type

Fiber array cable assembly

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Black
Color, boot B	Blue
Color, connector A	Green
Color, connector B	Blue
Construction Type	Stranded
Fibers per Subunit, quantity	12
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Male
Interface, Connector B	CS/UPC
Jacket Color	Yellow
Polarity	Method A
Total Fibers, quantity	12

Dimensions

Breakout Length	10 in 12 in
Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	10 – 999

ARGMXCSGD

Ordering Tree

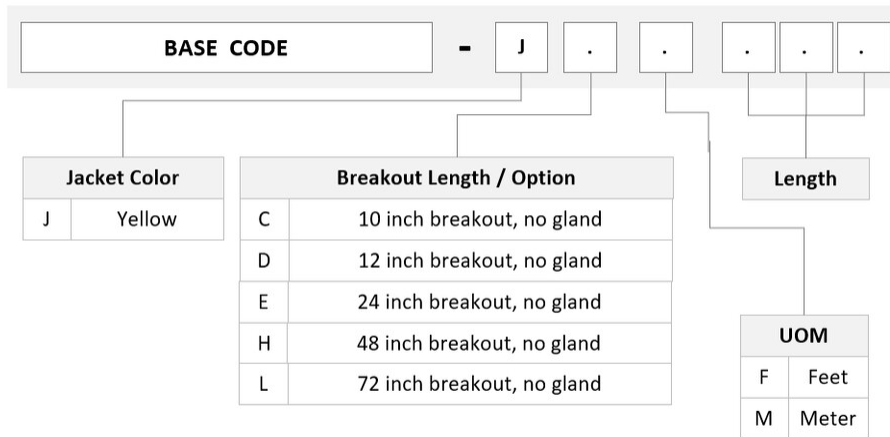

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Included Products

- 760237972 N-012-MP-8G1-F30YL/D – Fiber Indoor Cable, Low Smoke Zero Halogen Riser Light Duty MPO Patchcord Cable, 12 fiber, gel-free, singlemode G.657.A2/B2, feet jacket marking, yellow cable jacket color, Dca Flame Rating
- 860659010 – MPO-12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm