


FGS-MEXP-F-F/H-NC

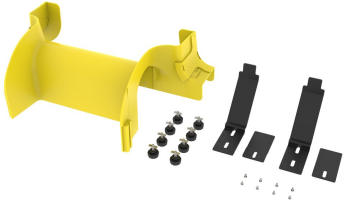

FiberGuide® 12-Inch Express Exit™, Cover Not Included, 4x12in, Yellow

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Express exit |
| Product Brand | FiberGuide® |
| Product Series | FGS |

General Specifications

| | |
|---------------------|--------------|
| Color | Yellow |
| Orientation | Horizontal |
| Section Type | Express exit |

Dimensions

| | |
|--------------------------|--|
| Height | 196.342 mm 7.73 in |
| Width | 558.8 mm 22 in |
| Length | 294.97 mm 11.613 in |
| System Dimensions | 102 mm x 305 mm (4 in x 12 in) 102 mm x 457 mm (4 in x 18 in) 102 mm x 610 mm (4 in x 24 in) |

Ordering Tree

FGS-MEXP-F-F/H-NC



Section Color

| | | |
|---|-------|--------|
| 9 | empty | yellow |
| | B | black |

Section Size

| | | |
|----|-----------|--|
| 10 | A/B/F | 4 x 4/6/12 in, with 2 x 2 in exit |
| | E-A/B/F | 4 x 4/6/12 in, with 4 x 4 in exit |
| | F-F/H-NC | 4 x 12/18/24 in, with 4 x 12 in exit, no cover |
| | G-A/B/F | 4 x 4/6/12 in, with 4 x 6 in exit |
| | LP-A/B/F | 4 x 4/6/12 in, with 2 x 2 in exit, low profile |
| | LP-CA | 4 x 4/6/12 in, with 2 x 4 in exit, low profile |
| | LP-G | 2 x 6 in, with 2 x 2 in exit, low profile |
| | GS-ABF-NC | 4 x 4/6/12 in, with 4 x 6 in exit, no cover |
| | CV | cover |
| | NC | no cover |

Material Specifications

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Packaging quantity 2

Weight, net 5.454 kg | 12.024 lb

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|---|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |

