


A-VF1-E0XXG

Base Product

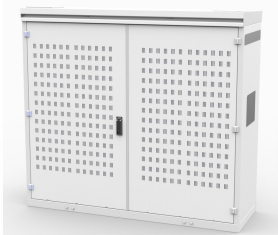

Cheshire Cabinet with rails and brackets fitted to accommodate up to 12 Ericsson Radios

- Includes fans with controller
- Supplied with 20 meter fan controller power cable
- Supplied with 20 meter alarm cable
- Contains two GPS windows (blanked and plastic covered)

Product Classification

| | |
|-----------------------|-----------------|
| Regional Availability | EMEA |
| Product Type | Outdoor cabinet |

General Specifications


| | |
|----------------------|--|
| Access | Double door |
| Accessories | Cable plate External alarm connection Hangers In-ground root Plinth |
| Cabinet Type | Combiner cabinet Radio cabinet |
| Cable Entry Location | Bottom |
| Color | Green (RAL 6009) Light Gray (RAL 7035) Others available at additional cost |
| Cooling | 175 mm fan (2) |
| Door Security | Internal door contact Swing handle with European profile cylinder |
| Door Type, front | Key lock (includedI) Non-removable |
| Door, quantity | 2 |
| Front Door Type | Single hinged |
| Lock Type | Key lock |
| Mounting | In-ground root Plinth |
| Radios Included | None |

Dimensions

| | |
|--------|-------------------------|
| Height | 1,721.866 mm 67.79 in |
| Width | 1,899.92 mm 74.8 in |
| Depth | 599.948 mm 23.62 in |

Dimension Drawing

A-VF1-EOXXG

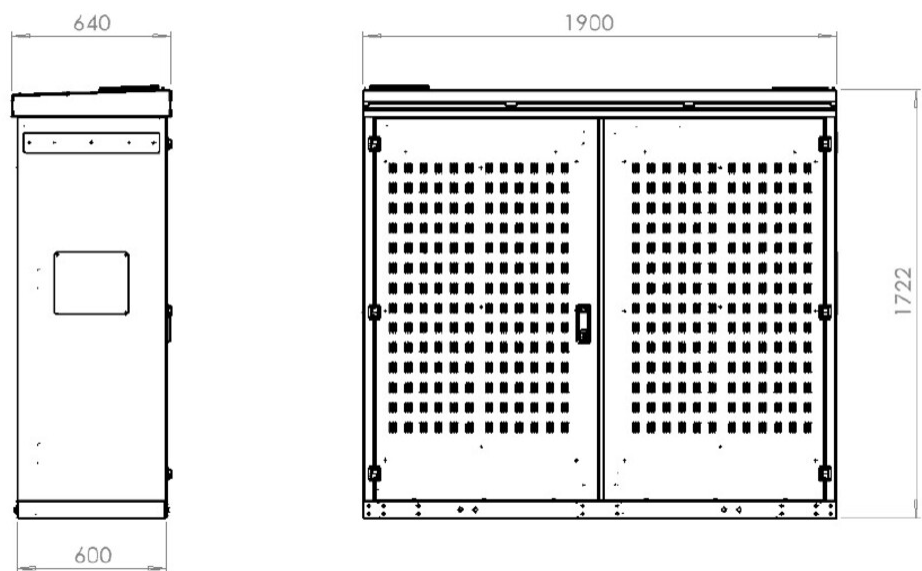

Material Specifications

| | |
|---------------|------------------|
| Finish | Powder coated |
| Material Type | Galvanized steel |

Environmental Specifications

| | |
|-------------------------|------|
| Qualification Standards | IP33 |
|-------------------------|------|

Packaging and Weights

| | |
|-------------|------------------------|
| Weight, net | 299.997 kg 661.38 lb |
|-------------|------------------------|

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |