


# 520095402 | HL4RPV-50-CBRSLAA

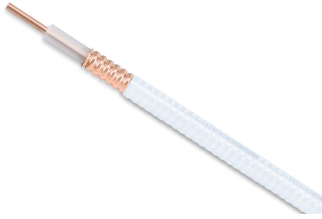

HL4-50, HELIAX® Plenum Rated Air Dielectric Coaxial Cable, corrugated copper, 1/2 in, off white PVC jacket

## Product Classification

**Product Type** Air coaxial cable

## VSWR/Return Loss

Frequency Band	VSWR	Return Loss (dB)
700–894 MHz	1.25	19.1
806–960 MHz	1.25	19.1
1700–2200 MHz	1.25	19.1
3550–3700 MHz	1.252	19.02
5150–5925 MHz	1.5	14

## Regulatory Compliance/Certifications

Agency	Classification
c(ETL)us Certification	CATVP/CMP
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
UL/ETL Certification	CATVP/CMP

