


# MUK-MSK4 | PIPE LEVELING KIT

---

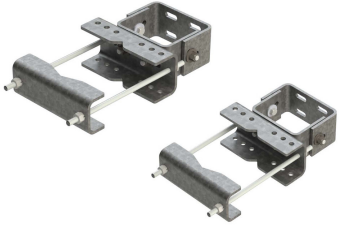

Tapered Pipe Mount Leveling Kit, attaches up to 8" OD or 60 degree angle Tower Legs, For Pipes 2-3/8" to 4-1/2" OD, U-Bolts sold separately

## Product Classification

**Product Type** Clamp set

## General Specifications

**Mounting** Round and angle legs

## Dimensions

**Mounting Diameter 2, maximum** 203.2 mm | 8 in

**Mounting Diameter, maximum** 114.3 mm | 4.5 in

**Mounting Diameter, minimum** 60.325 mm | 2.375 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Brackets | Clamp halves | Threaded rod

**Packaging quantity** 2