


MUK-MSK12 | UNIVERSAL CROSSOVER PLATE

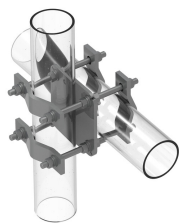

Universal Crossover Plate, connects up to 4-1/2" OD x 4-1/2" OD Pipe
(Pipe not included)

Product Classification

Product Type Clamp plate

General Specifications

Mounting Crossover plate

Dimensions

Mounting Diameter 2, maximum	114.3 mm 4.5 in
Mounting Diameter 2, minimum	42.164 mm 1.66 in
Mounting Diameter, maximum	114.3 mm 4.5 in
Mounting Diameter, minimum	42.164 mm 1.66 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included	Clamps Hardware Plates
Packaging quantity	1
Weight, net	10 kg 22.046 lb