


UNX2XLCBH

Base Product

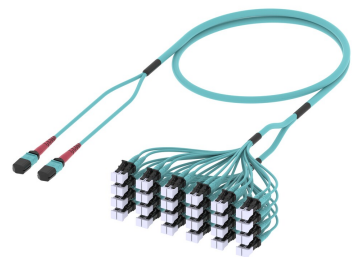

Ultra Low Loss ULL LazrSPEED® 550 MPO24(Pinned) to LC/UPC Ruggedized fanout Cable, 48-Fiber, LSZH, 24 fiber PmP 3.0mm Dca

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Red
Color, connector A	Aqua
Color, boot B	Blue
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	ULL
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	24
Total Fibers, quantity	48


Dimensions

Cable Assembly Length Range (m)	3 – 999
---------------------------------	---------

UNX2XLCBH

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

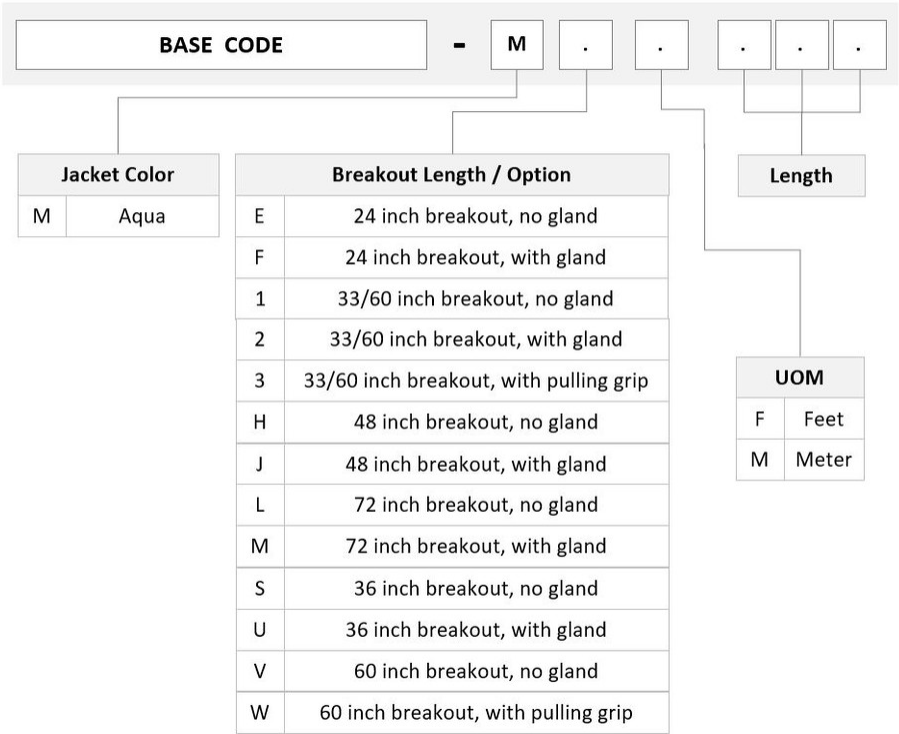

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance Dca

Environmental Space Dual Rated LSZH/Riser | Indoor

Included Products

760249075 N-048-MP-5K-F24AQ/30T/B2 – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber with 24-fiber, 3.0 mm subunits, Multimode OM4, Feet jacket marking, Aqua jacket color, B2ca flame rating

UNX2XLCBH

- | | | |
|-----------|---|------------------------------------------------|
| 860637425 | – | LC/UPC Connector, Multimode, Beige, Short Boot |
| 860662278 | – | MPO24,MALE,OM3/4,AQUA,3.0MM |