


# MTC4074M6996

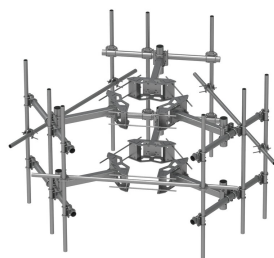

Three-Sector Double T-Arm Monopole Mount, Includes (2) Ring Mounts for 15"-50" OD Monopole, 6 ft x 3-1/2" OD face pipes, (9) 2-3/8" OD x 96" Antenna Pipes

## Product Classification

**Product Type** Monopole T-frame kit

## General Specifications

**Mounting** Monopole, 381–1270 mm (15–50 in) OD  
**Pipe, quantity** 9  
**Sectors, quantity** 4

## Dimensions

**Height** 2,438.4 mm | 96 in  
**Face Width** 1.829 m | 6 ft  
**Width** 1,828.8 mm | 72 in  
**Pipe Length** 2,438.4 mm | 96 in  
**Face Support Pipe Diameter** 88.9 mm | 3.5 in  
**Mounting Diameter, maximum** 1,270 mm | 50 in  
**Mounting Diameter, minimum** 381 mm | 15 in  
**Pipe Outer Diameter** 60.325 mm | 2.375 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** For Specifications, please contact your local ANDREW representative  
**Wind Rating Test Method** TIA/EIA-222-G

## Packaging and Weights

**Included** Frame | Pipe mounts | Plain end pipes | Ring mounts (2)

# MTC4074M6996

Packaging quantity	1
Weight, net	759.445 kg   1,674.29 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--