


Base Product

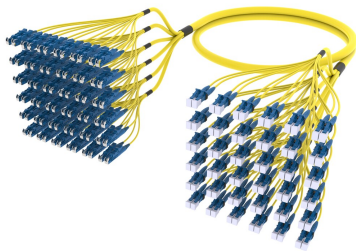

Ultra Low Loss ULL TeraSPEED® LSH to LC/UPC Grade B, Ruggedized fanout Cable, 72-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

## Product Classification

Regional Availability	Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Blue
Color, connector A	Blue
Color, boot B	Blue
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	LSH/UPC
Interface Feature, connector A	Grade B performance
Interface, Connector B	LC/UPC
Interface Feature, connector B	Grade B performance
Jacket Color	Yellow
Fibers per Subunit, quantity	12
Total Fibers, quantity	72

## Dimensions

Cable Assembly Length Range (m)	3 – 999
---------------------------------	---------

# UNGEDLFCK

Cable Assembly Length Range (ft)	8 – 999
Optical Specifications	
Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	Dca
Environmental Space	Dual Rated LSZH/Riser   Indoor

## Included Products

760242311 N-072-MP-8G-F12YL/20T/D	–	Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber multi-unit with 12 fiber 2.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
--------------------------------------	---	---