


U4GQPLUTU

Base Product

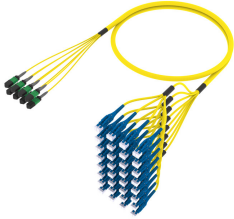

Singlemode MPO8 APC non-pinned to LC/UPC Uniboot Ruggedized fanout Cable, 64-Fiber, LSZH, 8 fiber PmP 2.0 mm /B2ca

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Europe |
| Portfolio | CommScope® |
| Product Type | Ruggedized fanout |
| Product Brand | Propel SYSTIMAX ULL |
| Ordering Note | For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications


| | |
|---------------------------------------|-------------------------|
| Connector A, quantity | 8 |
| Color, boot A | Gray |
| Color, connector A | Green |
| Connector B, quantity | 64 |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Construction Type | Stranded |
| Furcation Color | Yellow |
| Interface, Connector A | MPO-08/APC Female |
| Interface, Connector B | LC/UPC |
| Interface Feature, connector B | Uniboot |
| Jacket Color | Yellow |
| Polarity | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 8 |
| Total Fibers, quantity | 64 |

Dimensions

U4GQPLUTU

| | |
|---|----------|
| Breakout Length | 22 in |
| Cable Assembly Length Range (m) | 3 – 305 |
| Cable Assembly Length Range (ft) | 10 – 999 |

Ordering Tree

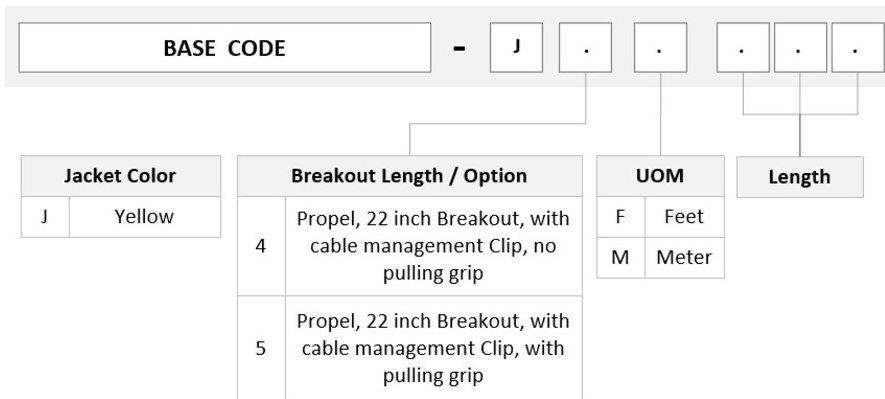

Mechanical Specifications

| | |
|--|-------------------------------|
| Cable Retention Strength, maximum | 11.24 lb @ 0° 4.40 lb @ 90° |
|--|-------------------------------|

Optical Specifications

| | |
|-------------------|----------------------|
| Fiber Mode | Singlemode |
| Fiber Type | G.657.A2, TeraSPEED® |

Environmental Specifications

| | |
|---|--------------------------------------|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
| EN50575 CPR Cable EuroClass Fire Performance | B2ca |
| Environmental Space | Dual Rated LSZH/Riser Indoor |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ANATEL | Compliant |
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |

U4GQPLUTU

UK-ROHS

Compliant/Exempted



Included Products

- | | | |
|---------------------------|---|--|
| 760254318 | - | Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 64 fiber with 2.0 mm Subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating |
| N-064-MP-8G1-F08YL/20T/B2 | | |
| 860658160 | - | LC/UPC Uniboot Connector, Singlemode, Blue |
| 860659028 | - | MPO-08, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 2mm |