


# U4GQXLUTU

## Base Product

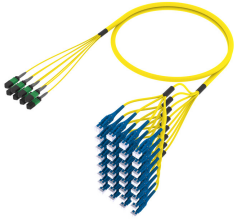

Singlemode MPO8 APC pinned to LC/UPC Uniboot Ruggedized fanout Cable, 64-Fiber, LSZH, 8 fiber PmP 2.0 mm /B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	8
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	64
<b>Color, boot B</b>	Blue
<b>Color, connector B</b>	Blue
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-08/APC Male
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	64

## Dimensions



# U4GQXLUTU

---

UK-ROHS

Compliant/Exempted



## Included Products

- |                           |   |  |
|---------------------------|---|--|
| 760254318                 | - | Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 64 fiber with 2.0 mm Subunits, |
| N-064-MP-8G1-F08YL/20T/B2 |   | Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating        |
| 860658160                 | - | LC/UPC Uniboot Connector, Singlemode, Blue   |
| 860659022                 | - | MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm                                       |