


# ULVQZLUTR

## Base Product

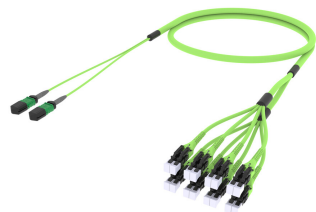

Ultra Low Loss ULL OM5 MPO8 APC pinned to LC/UPC Uniboot  
Ruggedized fanout Cable, 16-Fiber, Plenum, 8 fiber PmP 2.0 mm

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	Propel   SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


Connector A, quantity	2
Color, boot A	Gray
Color, connector A	Lime green
Connector B, quantity	16
Color, boot B	Lime green
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	16

## Dimensions

# ULVQZLUTR

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

## Ordering Tree

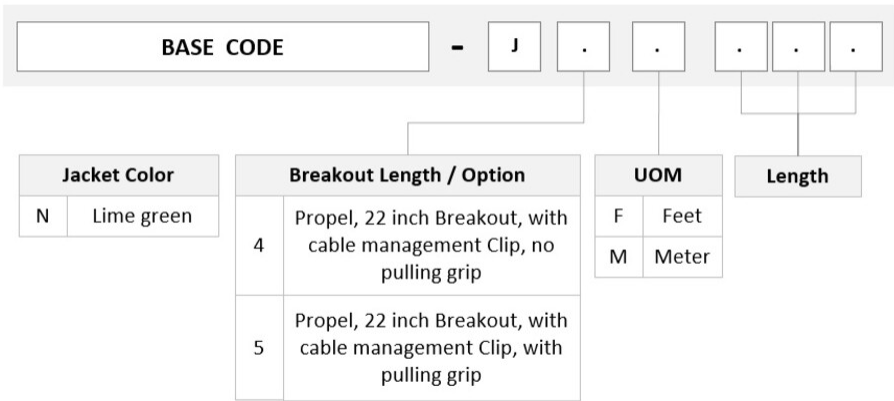

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor   Plenum

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# ULVQZLUTR

---



## Included Products

760248189	–	Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 16 fiber with 8 fiber subunits, Multimode
P-016-MP-5G-F08LM/20T		OM5, Feet jacket marking, Aqua jacket color
860658162	–	2.0 mm LC Uniboot GEN 1.5, Lime Green
860662230	–	MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm