

Base Product



Ultra Low Loss (ULL) OM5 MPO12 UPC (pinned) to Unconnectorized Fiber Trunk Cable Assembly, 288-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	PropeI   SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration


## General Specifications

Connector A, quantity	24
Color, boot A	Black
Color, connector A	Lime green
Connector B, quantity	0
Construction Type	Armored   Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	Unterminated
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	288

## Dimensions

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

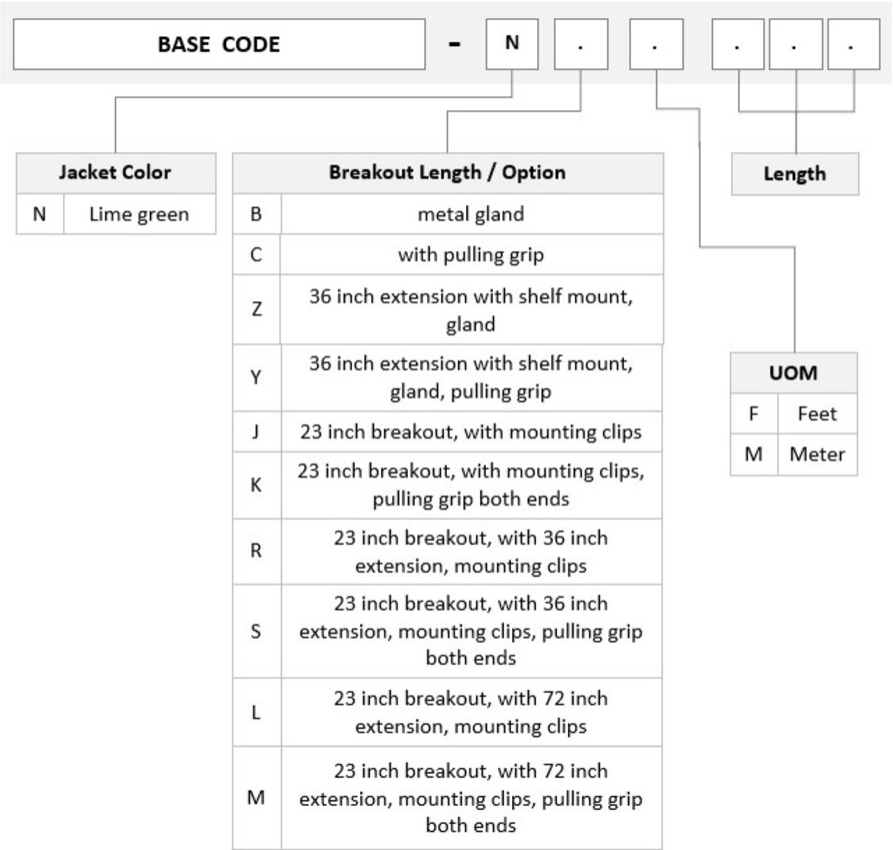

Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM5, LazrSPEED®

Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**EN50575 CPR Cable EuroClass Fire Performance** Dca  
**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760249687	-	Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored,
N-288-MZ-5G-F12AQ/20T/B2		Multimode OM5, 288 fiber multi-unit with 12 fiber subunits, Feet jacket marking, Lime-green jacket color, B2ca flame rating
860659008	-	MPO12, ULL, MALE, OM5, LIME, 2MM