

UKXMXMXCF

Base Product



Ultra Low Loss (ULL) OM4 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 24-Fiber, Armored Indoor Low Smoke Zero Halogen (LSZH)

Product Classification

| | |
|-----------------------|--|
| Regional Availability | Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber trunk cable assembly |
| Product Brand | PropeI SYSTIMAX ULL |
| Ordering Note | For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications

| | |
|------------------------------|-------------------------|
| Connector A, quantity | 2 |
| Color, boot A | Black |
| Color, connector A | Aqua |
| Connector B, quantity | 2 |
| Color, boot B | Black |
| Color, connector B | Aqua |
| Construction Type | Armored Stranded |
| Furcation Color | Aqua |
| Interface, Connector A | MPO-12/UPC Male |
| Interface, Connector B | MPO-12/UPC Male |
| Jacket Color | Aqua |
| Polarity | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 12 |
| Total Fibers, quantity | 24 |


Dimensions

| | |
|---------------------------------|---------|
| Cable Assembly Length Range (m) | 3 – 305 |
|---------------------------------|---------|

UKXMXMXCF

Cable Assembly Length Range (ft)10 – 999

Ordering Tree

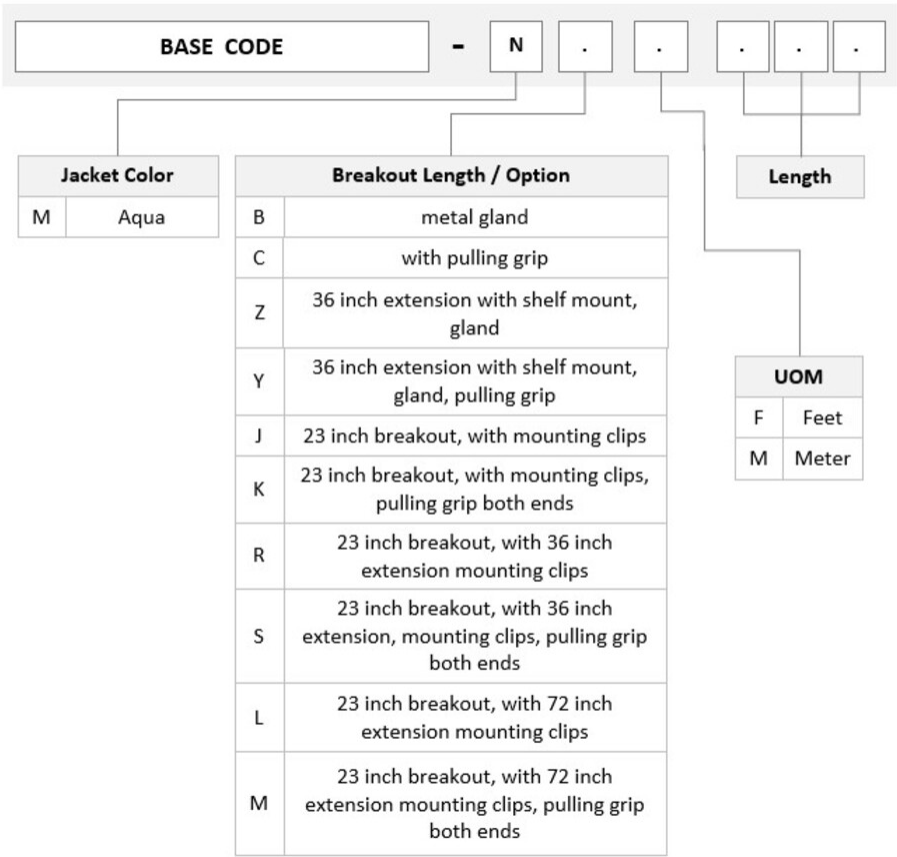

Mechanical Specifications

Cable Retention Strength, maximum11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber ModeMultimode
Fiber TypeOM4, LazrSPEED®

Environmental Specifications

Operating Temperature-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire PerformanceDca

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ANATEL | Compliant |
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

