


# UKXMXMXCP

Base Product

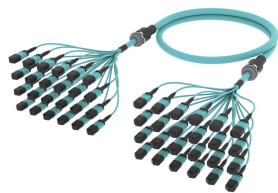

Ultra Low Loss (ULL) OM4 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 288-Fiber, Armored Indoor Low Smoke Zero Halogen (LSZH)

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel   SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Connector A, quantity	24
Color, boot A	Black
Color, connector A	Aqua
Connector B, quantity	24
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Armored   Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	MPO-12/UPC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	288


## Dimensions

Breakout Length	22 in
-----------------	-------

# UKXMXMXCP

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

## Ordering Tree

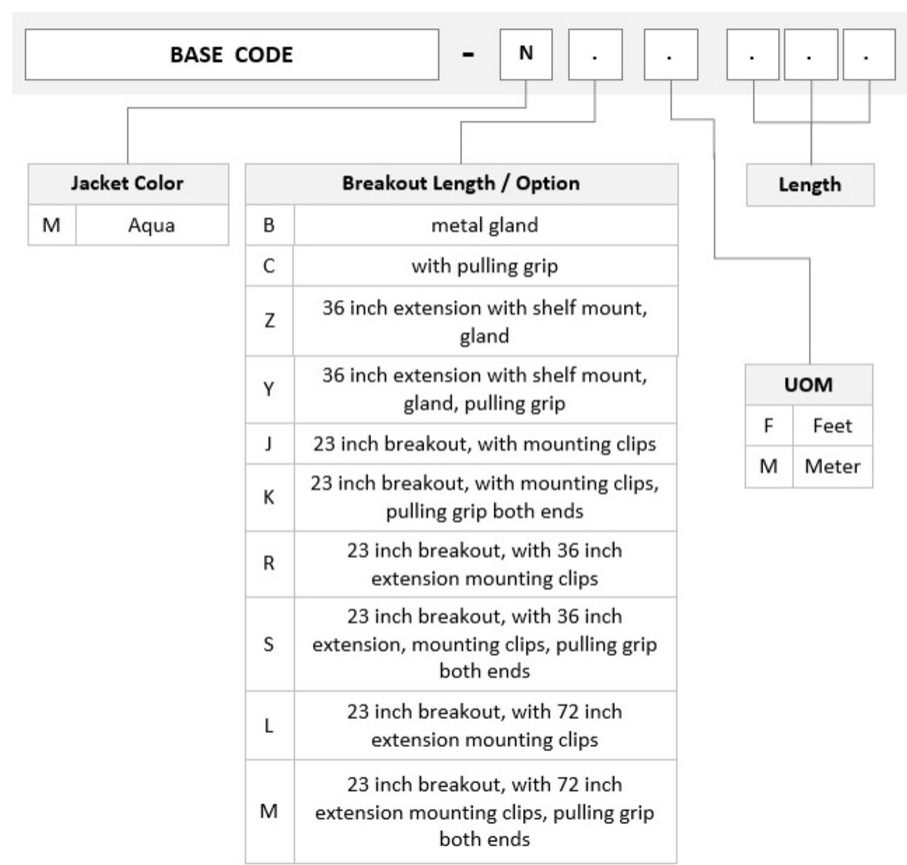

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
-----------------------	--------------------------------------

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760249678	–	Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 288 fiber multi-unit with 12 fiber subunits, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
N-288-MZ-5K-F12AQ/20T/B2		
860659006	–	MPO12, ULL, MALE, OM3/4, AQUA, 2MM