

UKXQZUCTF

Base Product



Ultra Low Loss (ULL) OM4 MPO8 APC (pinned) to Unconnectorized Fiber Trunk Cable Assembly, 24-Fiber, Armored Indoor Dual Rated (OFNR /LSZH)

Product Classification

| | |
|-----------------------|--|
| Regional Availability | Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber trunk cable assembly |
| Product Brand | Propel SYSTIMAX ULL |
| Ordering Note | For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |


General Specifications

| | |
|------------------------------|-------------------------|
| Connector A, quantity | 3 |
| Color, boot A | Gray |
| Color, connector A | Green |
| Connector B, quantity | 0 |
| Construction Type | Armored Stranded |
| Furcation Color | Aqua |
| Interface, Connector A | MPO-08/APC Male |
| Interface, Connector B | Unterminated |
| Jacket Color | Aqua |
| Polarity | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 8 |
| Total Fibers, quantity | 24 |

Dimensions

| | |
|----------------------------------|----------|
| Breakout Length | 22 in |
| Cable Assembly Length Range (m) | 3 – 305 |
| Cable Assembly Length Range (ft) | 10 – 999 |

Ordering Tree

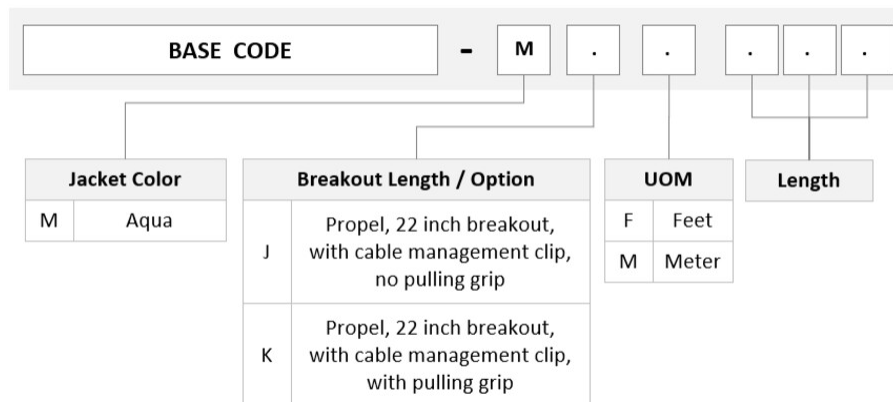

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM4, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system.

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted



Included Products

| | | |
|--------------------------|---|--|
| 760256016 | – | Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, |
| N-024-MZ-5K-F08AQ/20T/B2 | | Multimode OM4, 24 fiber, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating |
| 860662230 | – | MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm |