

# UKXRZUC8Q

## Base Product



Ultra Low Loss (ULL) OM4 MPO16 APC (pinned) to Unconnectorized, Fiber Trunk Cable Assembly, 128-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel   SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Connector A, quantity	8
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	0
Construction Type	Armored   Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-16/APC Male
Interface, Connector B	Unterminated
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	16
Total Fibers, quantity	128

## Dimensions


Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

# UKXRZUC8Q

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

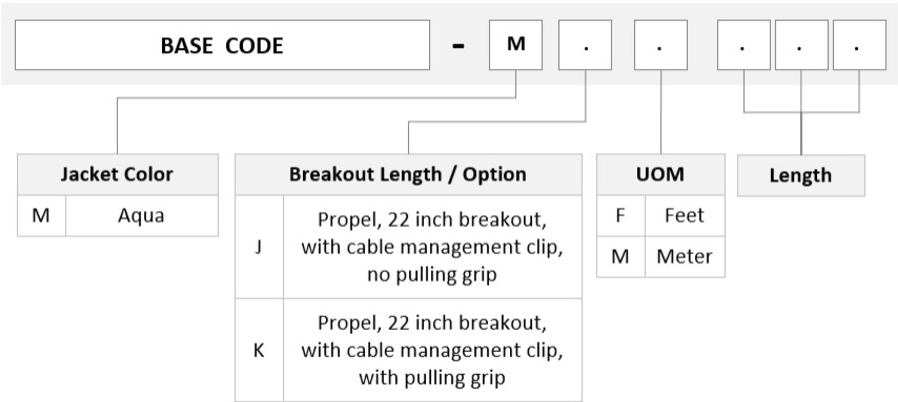

## Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM4, LazrSPEED®

## Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# UKXRZUC8Q

---



## Included Products

- |                          |   |  |
|--------------------------|---|--|
| 760256198                | – | Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, OM4 multi- |
| N-128-MZ-5K-F16AQ/30T/B2 |   | mode, 128 fiber, Feet jacket marking, Aqua jacket color, B2ca flame rating                 |
| 860659158                | – | Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, pinned, green, for 3 mm    |
|                          |   | cable  |