


# PM-SC2-96

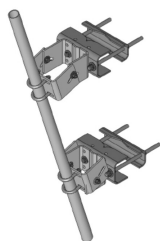

Universal Open Face Pipe Mount Kit, includes 2-3/8 in OD x 96 in pipe

## Product Classification

**Product Type** Pipe mount

## General Specifications

<b>Mounting</b>	Angle 60°, 203.2 mm (8 in)   Angle 90°, 152.4 mm (6 in)   Straight or tapered legs up to 203.2 mm (8 in) OD
<b>Note</b>	One 96 in x 8 in panel antenna per sector
<b>Pipe, quantity</b>	1
<b>Tower Taper</b>	Non-tapered   Tapered

## Dimensions

<b>Height</b>	2,438.4 mm   96 in
<b>Width</b>	304.8 mm   12 in
<b>Length</b>	304.8 mm   12 in
<b>Pipe Length</b>	2,438.4 mm   96 in
<b>Mounting Diameter, maximum</b>	203.2 mm   8 in
<b>Mounting Diameter, minimum</b>	0 mm   0 in
<b>Pipe Outer Diameter</b>	60.96 mm   2.4 in
<b>Stand-off Distance</b>	203.2 mm   8 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

<b>Wind Rating</b>	120 mph (BWS) at 150 ft AGL
<b>Wind Rating Test Method</b>	TIA/EIA-222

## Packaging and Weights

# PM-SC2-96

---

Included	Pipe   Sliding pipe mount brackets   Universal saddle mount
Packaging quantity	1
Weight, net	61.3 kg   135.143 lb

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

## \* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--