


# 1RU-SP2264001 | 1RU SPLTR PNL 2X64 UPC/LC

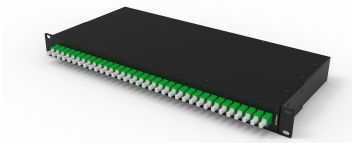

1RU panel, 2X64 split ratio, 1 splitter, LC/UPC connectors

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   EMEA   India   Latin America   North America
Product Type	Splitter module
Product Series	1RU

## General Specifications

Functionality	Splitting
Technology Type	Planar lightwave circuit (PLC)
Distribution Type	2 x 64 splitter
Interface, Input	LC/UPC
Interface, Output	LC/UPC
Splitter, quantity	1

## Dimensions

Height	43.69 mm   1.72 in
Width	482.6 mm   19 in
Length	199.89 mm   7.87 in

## Optical Specifications

Directivity, minimum	55 dB
Polarization Dependent Loss, maximum	0.4 dB
Uniformity, maximum	3.2 dB
Wavelength Range	1260–1650 nm
Insertion Loss, Splitter, maximum	21.8 dB
Return Loss, Splitter, minimum	50 dB

## Environmental Specifications

1RU-SP2264001 | 1RU SPLTR PNL 2X64 UPC/LC

---

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing

Packaging and Weights

Packaging quantity	1
--------------------	---