


# FQWMPMPHF

Base Product

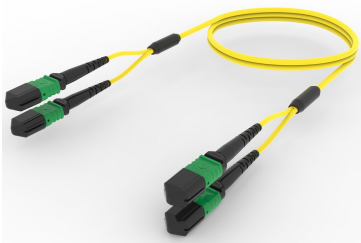

Singlemode, MPO/12(Unpinned) to MPO/12(Unpinned), InstaPATCH® 360 Array Cord, 24-Fiber, Plenum

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface Feature, connector A	Unpinned
Interface, Connector B	MPO-12/APC Female
Interface Feature, connector B	Unpinned
Jacket Color	Yellow
Polarity	Method B (LL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	24

## Dimensions

# FQWMPMPHF

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999
Diameter Over Jacket	3.6 mm   0.142 in

## Ordering Tree

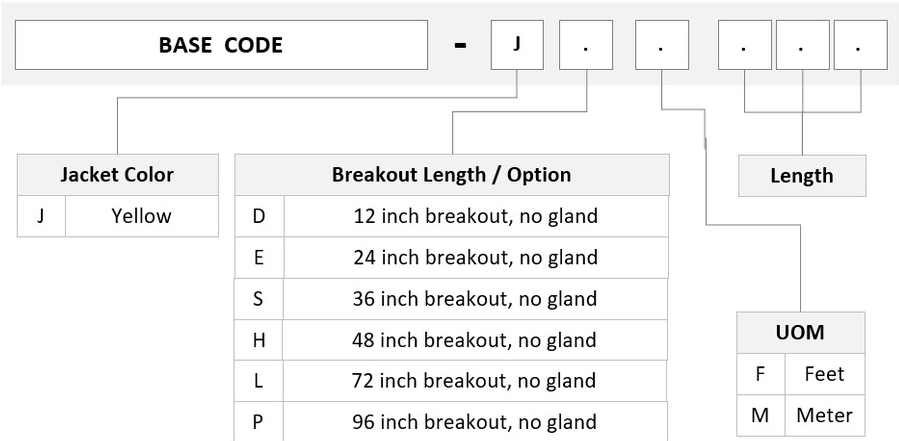

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor   Plenum

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# FQWMPMPHF

---



## Included Products

- |                    |   |   |
|--------------------|---|---|
| 760257038          | – | Fiber indoor cable, Plenum for MPO Light Duty Patchcords, 24 fiber, Singlemode G.657.A2/B2, |
| P-024-MP-8G1-F30YL |   | Feet jacket marking, Yellow jacket color  |
| 860638318          | – | MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm                                       |