

# RM-SM190-60

---



## Non-Penetrating Roof Mount

### Product Classification

**Product Type** Tripod mount

### General Specifications

**Mounting** Non-penetrating

**Pipe, quantity** 1

### Dimensions

**Height** 1524 mm | 60 in

**Width** 914.4 mm | 36 in


**Length** 0.914 m | 3 ft

**Pipe Length** 1524 mm | 60 in

**Pipe Outer Diameter** 48.26 mm | 1.9 in

# RM-SM190-60

## Outline Drawing

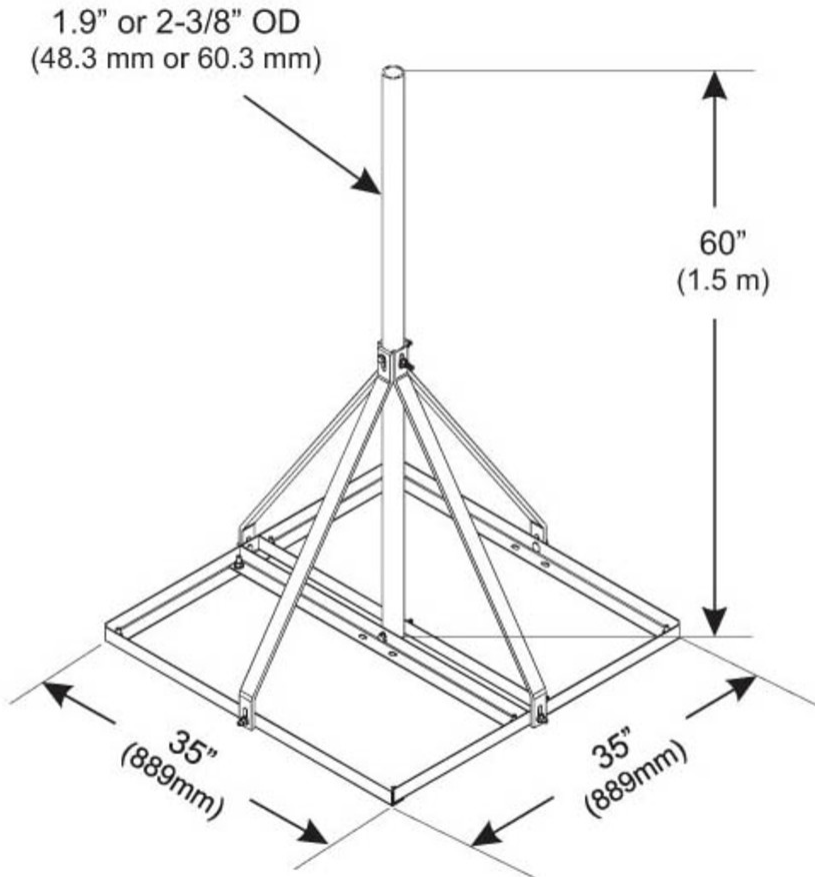

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** For Specifications, please contact [steelproducts@commscope.com](mailto:steelproducts@commscope.com) or call 800-255-1479

## Packaging and Weights

**Included** Ballast tray | Mast | Supports

**Packaging quantity** 1

**Weight, net** 27.2 kg | 59.966 lb

# RM-SM190-60

---

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



### \* Footnotes

**Wind Rating**                      BWS—Base Wind Speed; FBC—Florida Building Code