


SA-1C

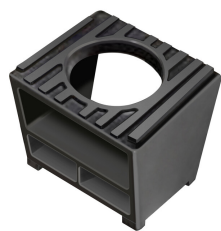

PIM-Guard®, Single-Way Snap-in Stand-off Adapter has a two slots for round member attachment. It includes one 3/4" hole for Snap-in hangers, supporting three stacks for 4-17mm or two stacks for 26-40mm cables

Product Classification

Product Type	Stand-off mount
Product Brand	PIM-Guard®
Ordering Note	ANDREW® standard product (Global)

General Specifications

Adapter Type	Stand-off adapter
Color	Black
Mounting	3/4 in through hole Round member

Dimensions

Inside Height	29.21 mm 1.15 in
Outside Width	29.972 mm 1.18 in
Outside Length	34.29 mm 1.35 in

Material Specifications

Material Type	Engineered polymer
---------------	--------------------

Mechanical Specifications

Maximum Loading	Triple stack for hangers SSH-47, SSH-710, SSH-1014, SSH-1416, SSH-411, SSH-1117
Vibration Survival	≥4 hours at resonant frequency

Environmental Specifications

Operating Temperature	-40 °C to +85 °C (-40 °F to +185 °F)
Environmental Strength Capability	Double cable weight
UV Resistance, minimum with no degradation	≥1000 hours

SA-1C

Packaging and Weights

Height, packed	17 cm 6.693 in
Width, packed	13 cm 5.118 in
Length, packed	10 cm 3.937 in
Packaging quantity	10
Weight, gross	0.15 kg 0.331 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.andrew.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

