


PIM-Guard® Applications

PIM-Guard Accessories, reduce the PIM where it matters most, the Hi-Risk PIM zone exists in close proximity to the antenna; in front, above, below, and even behind it. The zone is defined as:

- 10' (3M) directly above or below the antenna
- 5' (1.5M) behind the antenna
- 100' (30M) in front of the antenna

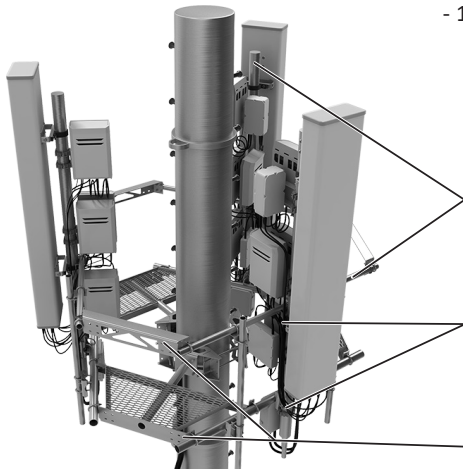

Mounting to Round Member for cable support

Material ID: PGP-series cable support brackets, SA-3C, SA-4C, SA-1C, UHA-3C, FBR-COIL-S

Supporting Fiber / Power / Coax cables

Material ID: SSH-411, SSH-1117, SSH-1724, SSH-2630, SSH-3642, SWH-200-10, SA-ISO, FBR-COIL-S

Mounting to Angle Iron for cable support

Material ID: UA-3C, SA-3C, SA-4C, UHA-3C, FBR-COIL-S

HELIAX® SnapTak® Adjustable Hangers (kits of 10)



Material ID:	Description:	Application:	Use with:	CommScope Cable series:
SSH-411	Polymer Snap-in Adjustable Hangers	Support cables from 4.0mm to 11.0mm in diameter.	3/4" stamped holes, PGP-series cable support brackets, UA-3C, SA-3C, SA-4C, SA-1TR, SA-1C, UHA-3C	DFJ-2S123 FJ-1S,2S,3S,4S,6S,8S, 12S DFJ-2S320 FHBDW-H2 FJ-4MM DFJ FJ-2SM, 4SM FJ-1SM FSJ1 PTS1 DFJ-12S RFFT ATCB-B01 (RET data cable)
SSH-1117	Polymer Snap-in Adjustable Hangers	Support cables from 11.0mm to 17.0mm in diameter.	3/4" stamped holes, PGP-series cable support brackets, UA-3C, SA-3C, SA-4C, SA-1TR, SA-1C, UHA-3C	PWRT-212-S LS2 PWRT-312-SC PWRT-208-LI PWRT-210-S FSJ4 HL4 AL4 LDF4 PWRT-208-S
SSH-1724	Polymer Snap-in Adjustable Hangers	Support cables from 17.0mm to 24.0mm in diameter.	3/4" stamped holes, PGP-series cable support brackets, UA-3C, SA-3C, SA-4C, SA-1TR, SA-1C, UHA-3C	HFA206-1 to 6S HFT410-1 to 4S PWRT-608-S PWRT-606-S
SSH-2630	Polymer Snap-in Adjustable Hangers	Support cables from 26.0mm to 30.0mm in diameter.	3/4" stamped holes, PGP-series cable support brackets, UA-3C, SA-3C, SA-4C, SA-1TR, SA-1C, UHA-3C	HFT206-8S PWRT-604-S AVA5
SSH-3642	Polymer Snap-in Adjustable Hangers	Support cables from 36.0mm to 42.0mm in diameter.	3/4" stamped holes, PGP-series cable support brackets, UA-3C, SA-3C, SA-4C, SA-1TR, SA-1C, UHA-3C	HFT1206 AVA6



[Installation Bulletin:](#)

HELIAX® SnapWrap Adjustable Hanger (kits of 10)



Material ID:	Description:	Application:	Use with:
SWH-200-10	Polymer Snap-in Adjustable Wrap Hanger	Bundle multiple cable types and sizes into a 1/2" (12.7mm) to 2" (50.8mm) bundle.	3/4" stamped holes, PGP-series cable support brackets, UA-3C, SA-3C, SA-4C, SA-1TR, SA-1C, UHA-3C

[Installation Bulletin:](#)



Cable Support Brackets



Material ID:	Description:	Application:	Use with:
PGP-CS04 , PGP-CS08 , PGP-CS10 , PGP-CS12 , PGP-CS16 , PGP-CS16L , PGP-CS18 , PGP-CS20-R , PGP-CS34L , PGP-CS38-R	Polymer 4 to 38 position cable support brackets	Antenna and RRU cable support brackets accommodate 8 to 76 cables. Up to 2 stackable hangers per position. Two 3/8" holes for threaded hardware.	All SnapTak and SnapStak hangers, SWH-200-10, CLICK Hanger Blocks

[Installation Bulletin:](#)



HELIAX® Angle Adapter (kits of 10)



Material ID:	Description:	Application:	Use with:
UA-3C	Polymer two hole angle adapter	Angle member attachment. Includes torque stop set bolt to ensure proper attachment force. Two 3/4" holes for Snap-in style hangers.	All SnapTak hangers, SWH-200-10

[Installation Bulletin:](#)




HELIAX® Standoff Adapters (kits of 10)



Material ID:	Description:	Application:	Use with:
SA-3C	Polymer three hole standoff adapter	Two sets of slots for round member attachment. 3/8" holes for bolt down attachment. Three 3/4" holes for Snap-in style hangers.	All SnapTak hangers, SWH-200-10

[Installation Bulletin:](#)

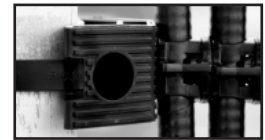

Material ID:	Description:	Application:	Use with:
SA-4C	Polymer three hole standoff adapter	Two sets of slots for round member attachment. 3/8" holes for bolt down attachment. Four 3/4" holes for Snap-in style hangers.	All SnapTak hangers, SWH-200-10

[Installation Bulletin:](#)



Material ID:	Description:	Application:	Use with:
SA-1TR	Polymer multi-function one hole standoff adapter	Threads into 3/8" & 1/2" bolts & U-bolts or snaps into 3/4" holes. One 3/4" hole for Snap-in style hangers.	All SnapTak hangers, SWH-200-10, 3/8" & 1/2" bolts

[Installation Bulletin:](#)




Material ID:	Description:	Application:	Use with:
SA-1C	Polymer one hole standoff adapter	Round member attachment. One 3/4" hole for Snap-in style hangers.	All SnapTak hangers, SWH-200-10

[Installation Bulletin:](#)



Material ID:	Description:	Application:	Use with:
UHA-3C	Polymer universal three hole standoff adapter	Round member or angle member attachment. Three 3/4" holes for snap-in hangers, or locations to mount three grommets or has a 3/8" holes for threaded rod attachment.	All SnapTak hangers, MCLICK hangers, cable grommets, SWH-200-10

[Installation Bulletin:](#)

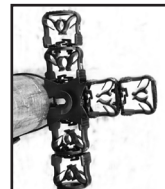

HELIAX® SnapStak Isolator (kits of 10)









Material ID:	Description:	Application:	Use with:
SA-ISO	Polymer one hole isolator for Snap-in Adjustable Hangers	Snaps in between hanger and mounting surface, and between stacked hangers to remove metal to metal contact.	3/4" stamped holes, all SnapStak® hangers



[Installation Bulletin:](#)

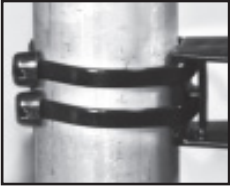

Banding

   	Material ID:	Description:	Application:	Use with:	 
	CB-12-16LH CB-12-18LH CB-12-27LH	Heat-stabilized weather resistant acetal cable banding, 1/2 in x 16 in, 18 in and 27 in length with attached locking head, 50, 100, 25 pcs	Round member or angle member attachment for polymer angle adapters and standoffs	SA-3C, SA-4C, SA-1C, UHA-3C	
	Material ID:	Description:	Application:	Use with:	
	CB-12-50	Cable Banding, Bulk, 1/2 in x 50 ft Reel	Round member or angle member attachment for polymer angle adapters, standoffs and excess cable management coilers	All Standoff adapters and FBR-COIL-S	
	Material ID:	Description:	Application:	Use with:	
	CB-LH-25	Locking Heads for Cable Banding CB-12-50, 25 pcs	Installation of CB-12-50 cable banding	CB-12-50	
	Material ID:	Description:	Application:	Use with:	
	CB-IT	Installation Tool for cable banding CB-12-50 and locking heads CB-LH-25	Installation and trim cutting of cable banding CB-12-50	CB-12-50 and CB-LH-25	

Excess Cable Management

	Material ID:	Description:	Application:	Use with:	
	FBR-COIL-S	Engineered plastic fiber coiling reel	Round member or angle member attachment. Accommodates 16' (5M) of excess 7mm fiber.	5-7mm fiber cables	

[Installation Bulletin:](#)

ANDREW an Amphenol company
2601 Telecom Parkway, Richardson, Texas, 75082, USA
www.andrew.com

Technical Support
+1 888 297 6433, Option 3 (Toll Free US and Canada)
awpnarsupport@andrew.com

Notice: ANDREW disclaims any liability or responsibility for the results of improper or unsafe installation, inspection, maintenance, or removal practices.
Aviso: ANDREW no acepta ninguna obligación ni responsabilidad como resultado de prácticas incorrectas o peligrosas de instalación, inspección, mantenimiento o retiro.
Avis : ANDREW décline toute responsabilité pour les conséquences de procédures d'installation, d'inspection, d'entretien ou de retrait incorrectes ou dangereuses.
Hinweis: ANDREW lehnt jede Haftung oder Verantwortung für Schäden ab, die aufgrund unsachgemäßer Installation, Überprüfung, Wartung oder Demontage auftreten.
Atenção: A ANDREW abdica do direito de toda responsabilidade pelos resultados de práticas inadequadas e sem segurança de instalação, inspeção, manutenção ou remoção.
Avvertenza: ANDREW declina eventuali responsabilità derivanti dall'esecuzione di procedure di installazione, ispezione, manutenzione e smontaggio improprie o poco sicure.
注意: ANDREW 公司申明對於不恰當或不安全的安裝、檢驗、維修或拆卸操作所導致的後果不負責任 何義務和責任

©2025 ANDREW, an Amphenol company. All rights reserved. Amphenol and ANDREW are registered trademarks of Amphenol and/or its affiliates in the U.S. and other countries. All product names, trademarks and registered trademarks are property of their respective owners.