


STS3-23

Three-way Snap-in Stand-off Adapter Kit for 2–3 in round members

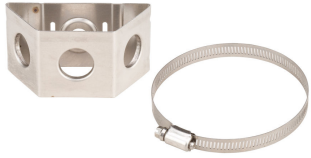

Product Classification

Product Type	Adapter
Product Brand	HELIAX®
Ordering Note	ANDREW® standard product in the United States and Canada

General Specifications

Adapter Type	Stand-off adapter
Mounting	3/4 in through hole

Dimensions

Outside Width	1,012.444 mm 39.86 in
Outside Length	1,975.104 mm 77.76 in
Compatible Diameter, maximum	76.2 mm 3 in
Compatible Diameter, minimum	50.8 mm 2 in
Material Thickness	2.591 mm 0.102 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	12 cm 4.724 in
Width, packed	11 cm 4.331 in

STS3-23

Length, packed	1 cm 0.394 in
Packaging quantity	10
Weight, gross	0.58 kg 1.279 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

31670-2	- Round Member Adapter for 2–3 in round members
SA-38	- Three-Way Snap-in Stand-off Adapter has two slots for round member attachment and 3/8" holes for angle adapter integration. It includes three 3/4" holes for Snap-in hangers

31670-2



Round Member Adapter for 2–3 in round members

Product Classification

Product Type	Adapter
Ordering Note	ANDREW® standard product (Global)

General Specifications

Adapter Type	Round member adapter
---------------------	----------------------

Dimensions

Compatible Diameter, maximum	76.2 mm 3 in
Compatible Diameter, minimum	50.8 mm 2 in
Material Thickness	0.711 mm 0.028 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Installation Torque, maximum	6.6 ft lb 8.948 N-m
Installation Torque, minimum	4.1 ft lb 5.559 N-m
Maximum Loading	Triple stack, 1-5/8 in cable

Packaging and Weights

Height, packed	14.2 cm 5.591 in
Width, packed	14.2 cm 5.591 in
Length, packed	7.9 cm 3.11 in
Packaging quantity	10
Weight, gross	0.38 kg 0.838 lb

Regulatory Compliance/Certifications

31670-2


Agency

ISO 9001:2015
REACH-SVHC

Classification

Designed, manufactured and/or distributed under this quality management system
Compliant as per SVHC revision on www.commscope.com/ProductCompliance

SA-38

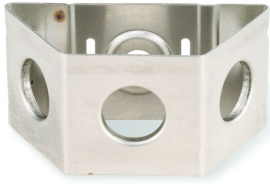

Three-Way Snap-in Stand-off Adapter has two slots for round member attachment and 3/8" holes for angle adapter integration. It includes three 3/4" holes for Snap-in hangers

Product Classification

Product Type	Adapter
Product Brand	HELIAX®
Ordering Note	ANDREW® standard product (Global)

General Specifications

Adapter Type	Stand-off adapter
Mounting	3/4 in through hole 3/8 in through hole Round member

Dimensions

Height	2.54 mm 0.1 in
Outside Width	41.402 mm 1.63 in
Outside Length	85.852 mm 3.38 in
Material Thickness	2.591 mm 0.102 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	12 cm 4.724 in
Width, packed	11 cm 4.331 in
Length, packed	1 cm 0.394 in
Packaging quantity	10

SA-38

Weight, gross 0.58 kg | 1.279 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

