


TP-MS-68

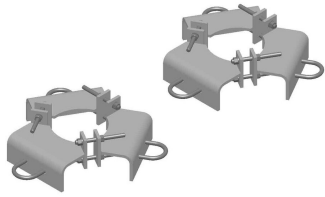

Multi-Sector Cluster Bracket, 6 in–8 in OD

Product Classification

Product Type Tripod mount component

General Specifications

Mounting Round member, 152.4–203.2 mm (6–8 in) OD

Dimensions

Height 101.6 mm | 4 in

Width 330.2 mm | 13 in

Length 0.335 m | 1.1 ft

Pipe Outer Diameter 60.96 mm | 2.4 in

Stand-off Distance 114.3 mm | 4.5 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Packaging and Weights

Included Brackets | U-bolts

Packaging quantity 1

Weight, net 21.2 kg | 46.738 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

TP-MS-68

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



* Footnotes

Wind Rating

BWS—Base Wind Speed; FBC—Florida Building Code