

TTS3-7515



Three-way Stand-off Adapter for 0.75–1.5 in round members, includes UAAI insert

Product Classification

Product Type	Adapter
Ordering Note	CommScope® non-standard product

General Specifications

Adapter Type	Stand-off adapter
Mounting	3/4 in through hole Round member

Dimensions

Material Thickness	2.591 mm 0.102 in
---------------------------	---------------------

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	12 cm 4.724 in
Width, packed	11 cm 4.331 in
Length, packed	1 cm 0.394 in
Packaging quantity	10
Weight, gross	0.58 kg 1.279 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

TTS3-7515

REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

- 31670-1 - Round Member Adapter for 1–2 in round members
- SA-38 - Three-way Snap-in Stand-off Adapter
- UAAI - Universal Angle Adapter Insert

31670-1



Round Member Adapter for 1–2 in round members

Product Classification

Product Type	Adapter
Ordering Note	CommScope® standard product (Global)

General Specifications

Adapter Type	Round member adapter
---------------------	----------------------

Dimensions

Compatible Diameter, maximum	50.8 mm 2 in
Compatible Diameter, minimum	25.4 mm 1 in
Material Thickness	0.711 mm 0.028 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Triple stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	15 cm 5.906 in
Width, packed	10 cm 3.937 in
Length, packed	10 cm 3.937 in
Packaging quantity	10
Weight, gross	0.23 kg 0.507 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system


31670-1

REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



SA-38

Three-way Snap-in Stand-off Adapter

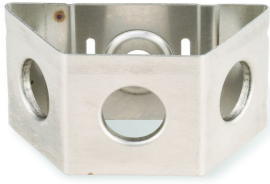

Product Classification

Product Type	Adapter
Ordering Note	CommScope® standard product (Global)

General Specifications

Adapter Type	Stand-off adapter
Mounting	3/4 in through hole 3/8 in through hole Round member

Dimensions

Height	2.54 mm 0.1 in
Outside Width	41.402 mm 1.63 in
Outside Length	85.852 mm 3.38 in
Material Thickness	2.591 mm 0.102 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	12 cm 4.724 in
Width, packed	11 cm 4.331 in
Length, packed	1 cm 0.394 in
Packaging quantity	10
Weight, gross	0.58 kg 1.279 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant





Universal Angle Adapter Insert

Product Classification

Product Type	Adapter
Ordering Note	CommScope® non-standard product

General Specifications

Adapter Type	Adapter
Mounting	3/8 in tapped hole

Dimensions

Outside Width	12.7 mm 0.5 in
Outside Length	25.4 mm 1 in
Material Thickness	12.7 mm 0.5 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Triple stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	4 cm 1.575 in
Width, packed	5 cm 1.969 in
Length, packed	1 cm 0.394 in
Packaging quantity	10
Weight, gross	0.13 kg 0.287 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value

UAAI

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

