


2105093-8

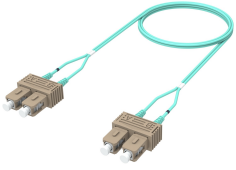

Fiber Optic Patch Cord, Duplex, OM4, SC/UPC to SC/UPC, LSZH & OFNR, aqua, 8 m

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	210

General Specifications

Connector A, quantity	2
Color, boot A	Beige
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Beige
Color, connector B	Beige
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Total Fibers, quantity	2

Dimensions

Cord Length	8 m 26.247 ft
Diameter Over Jacket	1.8 mm 0.071 in

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.3 dB

2105093-8

Environmental Specifications

Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

