

# 8-2105061-0



Fiber Optic Patch Cord, Duplex, Multimode, LC/UPC to LC/UPC, LSZH & OFNR, aqua, 80 m

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   India   Latin America
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	210

## General Specifications


Connector A, quantity	2
Color, boot A	Aqua
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Aqua
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Total Fibers, quantity	2

## Dimensions

Cord Length	80 m   262.467 ft
Diameter Over Jacket	1.8 mm   0.071 in

## Ordering Tree

# 8-2105061-0

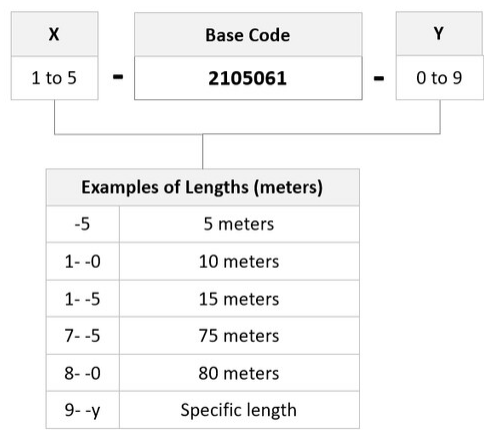

## Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®
Insertion Loss, maximum, connector A and B	0.3 dB

## Environmental Specifications

Environmental Space	Dual Rated LSZH/Riser
Qualification Standards	IEC 60332-1   IEC 60332-3   IEC 60754   IEC 61034

## Packaging and Weights

Packaging quantity	1
--------------------	---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

# 8-2105061-0

---

**Insertion Loss, maximum, connector A and B** Insertion loss is measured at a room temp of +20°C (+68°F)