


# 1-2105027-9

---

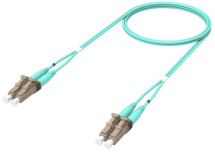

Fiber Optic Patch Cord, OM3, LC to LC duplex, 1.8 mm LSZH & OFNR, 19 m, aqua

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   India |
| <b>Portfolio</b>             | CommScope®                                   |
| <b>Product Type</b>          | Fiber patch cord, duplex                     |
| <b>Product Series</b>        | 210  |

## General Specifications

|                               |                |
|-------------------------------|----------------|
| <b>Connector A, quantity</b>  | 2              |
| <b>Color, boot A</b>          | Beige          |
| <b>Color, connector A</b>     | Beige          |
| <b>Connector B, quantity</b>  | 2              |
| <b>Color, boot B</b>          | Beige          |
| <b>Color, connector B</b>     | Beige          |
| <b>Interface, Connector A</b> | LC/UPC         |
| <b>Interface, Connector B</b> | LC/UPC         |
| <b>Jacket Color</b>           | Aqua           |
| <b>Polarity</b>               | Pairs, flipped |
| <b>Total Fibers, quantity</b> | 2              |

## Dimensions

|                             |                   |
|-----------------------------|-------------------|
| <b>Cord Length</b>          | 19 m   62.336 ft  |
| <b>Diameter Over Jacket</b> | 1.8 mm   0.071 in |

## Ordering Tree

# 1-2105027-9



## Optical Specifications

|   |                 |
|---|-----------------|
| <b>Fiber Mode</b>                           | Multimode       |
| <b>Fiber Type</b>                           | OM3, LazrSPEED® |
| <b>Insertion Loss, maximum, connector A</b> | 0.3 dB          |
| <b>Insertion Loss, maximum, connector B</b> | 0.3 dB          |
| <b>Return Loss, minimum, connector A</b>    | 20 dB           |
| <b>Return Loss, minimum, connector B</b>    | 20 dB           |

## Environmental Specifications

|                                |   |
|--------------------------------|---|
| <b>Environmental Space</b>     | Dual Rated LSZH/Riser                             |
| <b>Qualification Standards</b> | IEC 60332-1   IEC 60332-3   IEC 60754   IEC 61034 |

## Packaging and Weights

|                           |   |
|---------------------------|---|
| <b>Packaging quantity</b> | 1 |
|---------------------------|---|

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>   |
|---------------|---|
| CHINA-ROHS    | Above maximum concentration value   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted  |
| UK-ROHS       | Compliant   |

1-2105027-9

---

